


Сборочные детали для компонентов повышенной прочности, винт со сфероцилиндрической головкой и резьбовым соединением, под отвертку Torx, M4 x 14

CATALOG NUMBER

24566-102

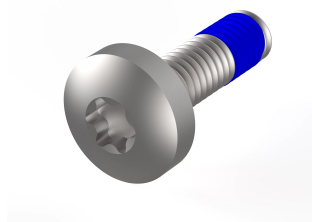

Детали для сборки с резьбовым соединением для прочной боковой панели, горизонтальной рейки, заглушек, заднего уголка.

CERTIFICATIONS



FEATURES

Винты для следующих креплений: прочная боковая панель — горизонтальная рейка, Прочная боковая панель — заглушка, прочная боковая панель — задний уголок

PRODUCT ATTRIBUTES

Type: Panhead Screw

Длина мм: 14mm

Package Quantity: 100

Thread Size: M4

Material: Нержавеющая сталь

Product Family: EuropacPRO

Product Type: Монтажные детали

Works With: Блочный каркас

Net Weight: 0.22kg

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE