


Горизонтальная рейка типа Н-VT, усиленный, с ЭМС-прокладкой, 42 HP

CATALOG NUMBER

24576-042

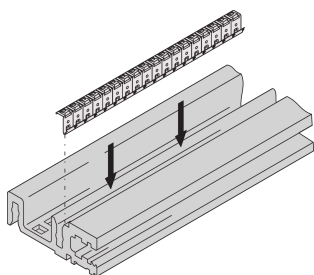

Горизонтальная рейка и прокладка из нержавеющей стали могут использоваться для создания экранированного корпуса PropacPRO. Комплект обеспечивает экранирование между горизонтальной рейкой и верхней крышкой.

CERTIFICATIONS



FEATURES

Для заглушек на экранированных корпусах

Алюминиевый экструдированный профиль, анодированная поверхность, электропроводящая контактная поверхность, без HP-маркировки

С ЭМС-прокладкой из нержавеющей стали

PRODUCT ATTRIBUTES

Rack Width: 42HP

Package Quantity: 1

Finish: Anodized

Длина мм: 218.44mm

Material: Алюминий

Product Family: EuropacPRO; RatiopacPRO; RatiopacPRO AIR; CompacPRO; PropacPRO

Product Type: Горизонтальный рельс

Type: Heavy, VT

Works With: Блочный каркас; Coffrets

Net Weight: 0.095kg

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE