


Система CPCI с PSB, высота 10 U, 14 слотов

CATALOG NUMBER

24579-028

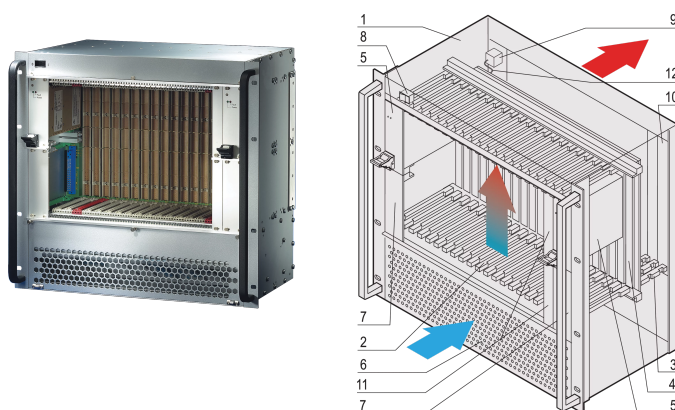

Система 10 U CompactPCI с PSB для четырнадцати печатных плат 6 U, четырнадцати печатных плат RTM и до четырех сменных источников питания 3U.

CERTIFICATIONS



FEATURES

Система соответствует IEC60297-3-101, -102, -103 IEEE 1101.1, 1101,10/11 объединительная плата соответствует PICMG ред. 2,16

Система с вертикальным каркасом для печатных плат. Фронтальная плата: 6 U, глубина 160 мм; Задняя панель ввода-вывода: 6 U, глубина 80 мм

Объединительная плата, PSB (объединительная плата с коммутацией пакетов), PICMG 2.16 16 слотов, 6 U, 64-разрядная (2 коммуникационных слота, 14 узловых слотов)

Отвод тепла с помощью модуля вентиляторов, от передней части к задней

Два 19-дюймовых источника питания CompactPCI, 250 Вт (3 U, 8 HP), подготовлена к установке двух дополнительных 19-дюймовых совместимых источников питания

Подготовлена для мониторинга системы при помощи модуля мониторинга шасси (CMM)

PRODUCT ATTRIBUTES

Product Type: System

Number of Slots: 16

Type: 19" Rack Mount

Backplane Type: 6 U CompactPCI with PSB

Data Transfer: 64-bit PCI Bus; GbE

Power per Slot: 40W

Input Voltage AC: 100 – 240V

Airflow Direction: Front to Rear

Rack Height: 10U

Power Supply Type: (2) Pluggable AC PSU

Power Supply Included: Да

Rear I/O: Да

Complies With: PICMG 2.0 R3.0

Глубина мм: 275mm

Высота мм: 443.7mm

Net Weight: 20kg

Package Quantity: 1

ADDITIONAL PRODUCT DETAILS

Модифицированные системы доступны по запросу.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE