


Боковая крышка со стороны пайки печатной платы, CPCI, 6 U, 233,35 x 80 мм,

CATALOG NUMBER

24579-039

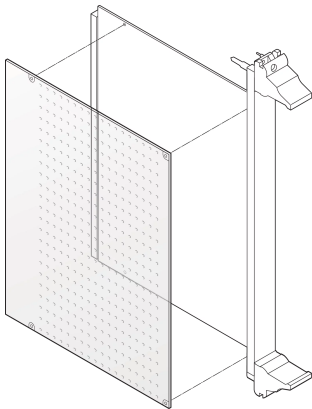

Боковая крышка механически защищает поверхность пайки печатной платы.

CERTIFICATIONS



FEATURES

Крышка перфорирована для лучшего охлаждения компонентов

Механическая защита стороны пайки

PRODUCT ATTRIBUTES

Rack Height: 6U

Package Quantity: 1

Глубина мм (D): 80mm

Material: Plastic

Product Type: Крышка

Type: Solder Side Cover

Ширина мм (W): 233.35mm


Works With: Передние панели

Net Weight: 0.014kg

ADDITIONAL PRODUCT DETAILS

Для монтажа перфорированных крышек требуются фиксирующие зажимы; заказываются отдельно.

DIAGRAMS

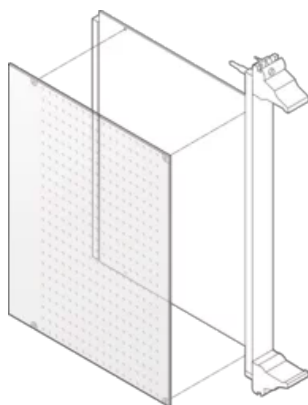

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE