


# Система CPPI для подключаемого источника питания АТХ, горизонтальная, высота 2 U, 4 слотов

## CATALOG NUMBER

**24579-082**

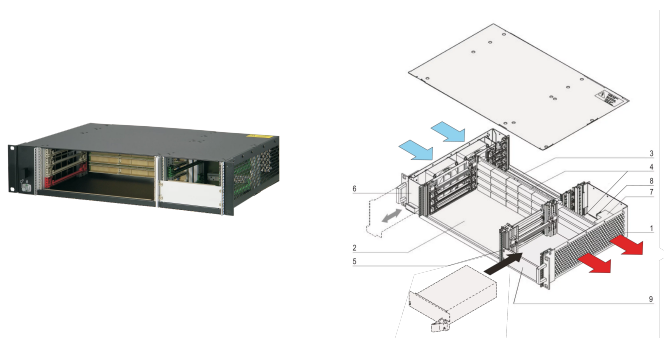

Система 2 U CompactPCI с горизонтальным каркасом для печатных плат на четыре платы 6 U, четыре платы RTM и один сменный источник питания CompactPCI 3 U. Возможность установки второго сменного источника питания.

## CERTIFICATIONS



## FEATURES

Система соответствует IEC 60297-3-101, -102, -103; IEEE 1101.1, 1101.10/11; объединительная плата соответствует PICMG 2.0 верс. 3,0

Система с горизонтальным каркасом для печатных плат. Фронтальная плата: 6 U, глубина 160 мм; Задняя панель ввода-вывода: 6 U, глубина 80 мм

Объединительная плата (объединительная плата для сигналов и питания как одно целое) 4 слотов, 6 U, 64-разрядная; системный слот слева, разъем питания (2x P47)

Отвод тепла с помощью вентилятора с горячей заменой (воздушный поток слева направо)

Подготовлена для установки 19-дюймового источника питания CompactPCI (3 U, 8 HP)

## PRODUCT ATTRIBUTES

---

Product Type: System

Number of Slots: 4

Type: 19" Rack Mount

Backplane Type: 6 U CompactPCI

Data Transfer: 64-bit PCI Bus

Power per Slot: 40W

Input Voltage AC: 100 – 240V

Airflow Direction: Left to Right

Rack Height: 2U

Power Supply Type: (1) Pluggable PSU

Power Supply Included: Нет

Rear I/O: Да

Complies With: PICMG 2.0 R3.0

Глубина мм: 275mm

Высота мм: 88.1mm

Ширина мм: 449mm

Net Weight: 7.82kg

Package Quantity: 1

## ADDITIONAL PRODUCT DETAILS

---

Модифицированные системы доступны по запросу.

Вариант исполнения на 48 В пост. тока по запросу.

## WARNING

---

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**