


Система CompactPCI с подключаемым источником питания, PSB H.110, высота 4 U, 8 слотов

CATALOG NUMBER

24579-135

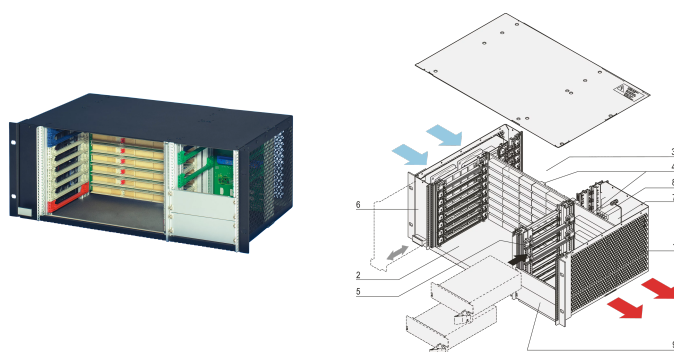

Система 4 U CompactPCI с PSB и H.110, с горизонтальным каркасом для печатных плат на восемь плат 6 U, восемь плат RTM и двумя сменными источниками питания CompactPCI 3 U. Возможность установки до четырех сменных источников питания.

CERTIFICATIONS



FEATURES

Система соответствует IEC60297-3-101, -102, -103 IEEE 1101.1, 1101,10/11 объединительная плата соответствует PICMG ред. 2,16

Система с горизонтальным каркасом для печатных плат. Фронтальная плата: 6 U, глубина 160 мм; Задняя панель ввода-вывода: 6 U, глубина 80 мм

Монолитная объединительная плата для (сигналов и питания) 64-разрядных CompactPCI; PSB (объединительная плата с коммутацией пакетов), PICMG 2.16; H.110, 8 слота, 6 U, 64-разрядная CompactPCI (2 слота коммутаторов, 6 узловых слотов H.110), системный слот слева; интегрированная силовая объединительная плата с 2 разъемами P 47

Отвод тепла при помощи вентилятора с горячей заменой, воздушный поток слева направо

Готова к размещению двух 19-дюймовых источников питания CompactPCI 250Вт (3 U, 8 HP)

PRODUCT ATTRIBUTES

Product Type: System
Number of Slots: 8
Type: 19" Rack Mount
Backplane Type: 6 U CompactPCI with PSB and H.110
Data Transfer: 64-bit PCI Bus; GbE
Power per Slot: 40W
Input Voltage AC: 100 – 240V
Airflow Direction: Left to Right
Rack Height: 4U
Power Supply Type: (2) Pluggable PSU
Power Supply Included: Нет
Rear I/O: Да
Complies With: PICMG 2.0 R3.0
Глубина мм: 275mm
Высота мм: 177mm
Package Quantity: 1

ADDITIONAL PRODUCT DETAILS

Модифицированные системы доступны по запросу.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE