


Система CompactPCI с источником питания АТХ. Настольный корпус, высота 4 U, 8 слотов, ширина стойки 84 HP

CATALOG NUMBER

24579-602

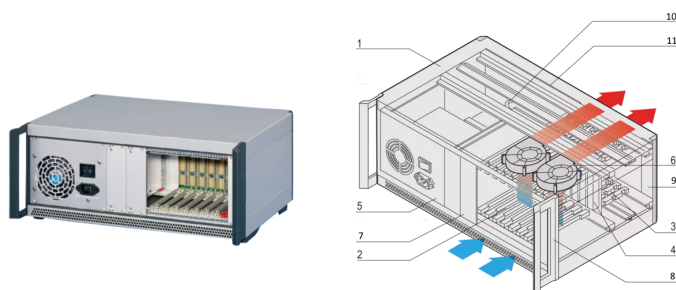

Настольное шасси CompactPCI с вертикальным каркасом для печатных плат на восемь плат 3 U, восемь плат RTM 3 U и одним встроенным источником питания АТХ.

CERTIFICATIONS



FEATURES

Система соответствует IEC 60297-3-101, -102, -103; IEEE 1101.1, 1101.10/11; объединительная плата соответствует PICMG 2.0 верс. 3,0

Система с вертикальным каркасом для печатных плат. Фронтальная плата: 3 U, глубина 160 мм; Задняя панель ввода-вывода: 3 U, глубина 80 мм

Объединительная плата с 8 слотами, 3 U, 32-битная, системный слот справа; Допускается использование ЦП шириной 8 HP

Отвод тепла осуществляется двумя радиальными вентиляторами, воздушный поток спереди назад

Блок питания АТХ, 300 Вт

Возможность установки DVD-дисков Slim-Line и жесткого диска

PRODUCT ATTRIBUTES

Product Type: System

Number of Slots: 8

Type: Настольный корпус

Backplane Type: 3 U CompactPCI

Data Transfer: 32-bit PCI Bus

Power per Slot: 40W

Input Voltage AC: 100 – 240V

Airflow Direction: Front to Rear

Rack Height: 4U

Power Supply Type: (1) ATX PSU

Power Supply Included: Да

Rear I/O: Да

Complies With: PICMG 2.0 R3.0

Глубина мм: 275mm

Высота мм: 177mm

Net Weight: 10.7kg

Package Quantity: 1

ADDITIONAL PRODUCT DETAILS

Модифицированные системы доступны по запросу.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE