
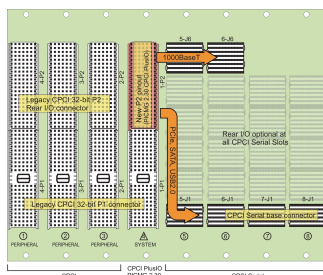


Система CPCI PlusIO, настольная, высота 4 U, 8 слотов, ширина стойки 44 HP

CATALOG NUMBER

24579-605

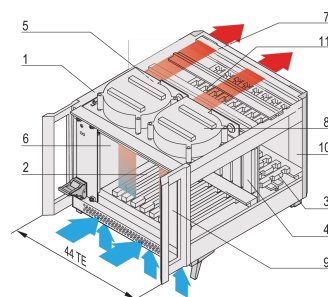

Настольное шасси CompactPCI PlusIO с вертикальным каркасом для печатных плат для одного системного контроллера CPCI PlusIO, 4 периферийных плат CompactPCI и 3 плат CompactPCI Serial.

CERTIFICATIONS



FEATURES

Система соответствует IEC 60297-3-101, -102, -103; IEEE 1101.1, 1101.10/11; объединительная плата соответствует PICMG 2.0 верс. 3,0 и PICMG 2.30 верс. 1,0

Система с вертикальным каркасом для печатных плат. Фронтальная плата: 3 U, глубина 160 мм; Задняя панель ввода-вывода: 3 U, глубина 80 мм

Объединительная плата с 4 слотами, 3 U, 32-битная, CompactPCI; 4 слота, 3 U, CompactPCI PlusIO

Отвод тепла осуществляется двумя радиальными вентиляторами, воздушный поток спереди назад

19-дюймовый блок питания, 250 Вт, 3 U, 8 HP

PRODUCT ATTRIBUTES

Product Type: System

Number of Slots: 8

Type: Настольный корпус

Backplane Type: 3 U, 4 Slot CompactPCI and 4 Slot CompactPCI Serial

Data Transfer: 32-bit PCI Bus; PCIe Gen2

Power per Slot: 30W

Input Voltage AC: 100 – 240V

Airflow Direction: Front to Rear

Rack Height: 4U

Power Supply Type: (1) Pluggable PSU

Power Supply Included: Да

Rear I/O: Да

Complies With: PICMG 2.30 R1.0

Глубина мм: 275mm

Высота мм: 177mm

Package Quantity: 1

ADDITIONAL PRODUCT DETAILS

Модифицированные системы доступны по запросу.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE