
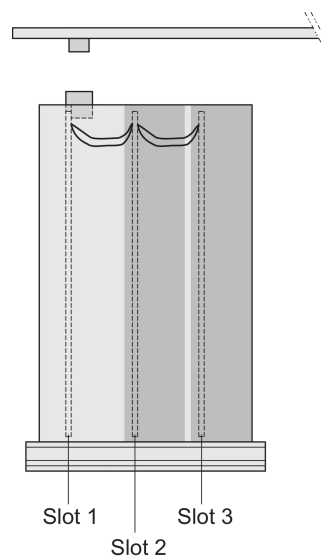
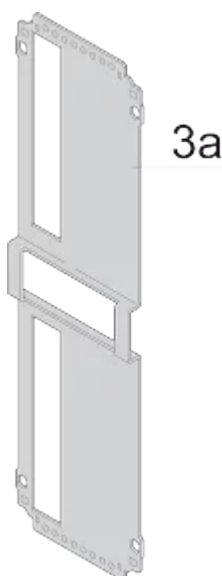
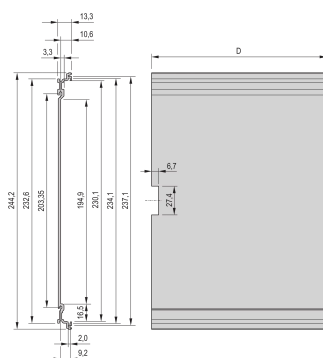
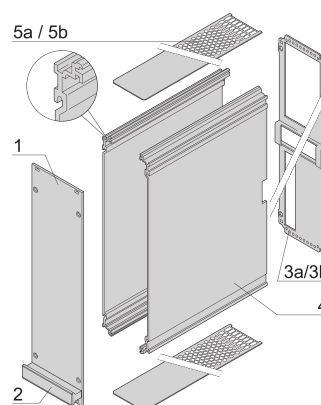


# Набор для монтажа вставных блоков рамного типа PRO, перфорированные крышки, 1 разъем, высота 6 U, ширина стойки 12 HP, 227 мм

CATALOG NUMBER

**24812-762**

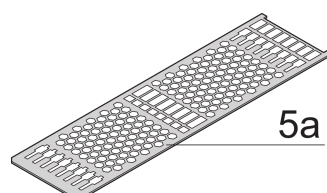

Сменный блок рамного типа, неэкранированный, перфорированная верхняя/нижняя крышка, задняя панель с вырезом для одного разъема.

## CERTIFICATIONS

---



## FEATURES

---

Экструдированные боковые панели справа и слева, с канавками для вставки печатной платы (стандартное положение платы только слева)

Задняя стенка с выемкой для одного разъема (соответствует EN 60603, DIN 41612, типы конструкции: B, C, D, F, H, Q, R, S)

Верхняя крышка с перфорацией, для направляющих (воздушный поток прибл. 60 %); направляющие заказываются отдельно

## PRODUCT ATTRIBUTES

---

Rack Height: 6U

Rack Width: 12HP

Package Quantity: 1

Handle Type: Trapezoid

Rear Panel Type: Single Connector Cut-Out

Cover Plate Type: Cover Plate with Perforation for Guide Rails

Front Finish: Anodized

Rear Finish: Anodized

Cooling: С перфорацией

Глубина мм (D): 227mm

EMC Shielding: Нет

Finish: Anodized

Material: Алюминий

Product Type: Cassette


Type: Frame Type Plug-in Units PRO

## ADDITIONAL PRODUCT DETAILS

---

To fit further boards without rear connector, guide rail (part no. 24812-301) and 'Board fixing from slot 2' (part no. 24812-301 + screw part no. 24560-178) are required, 2 guide rails, 2 rear panel holders and board fixing for slot 1 and one slot 2 are already included.

## DIAGRAMS

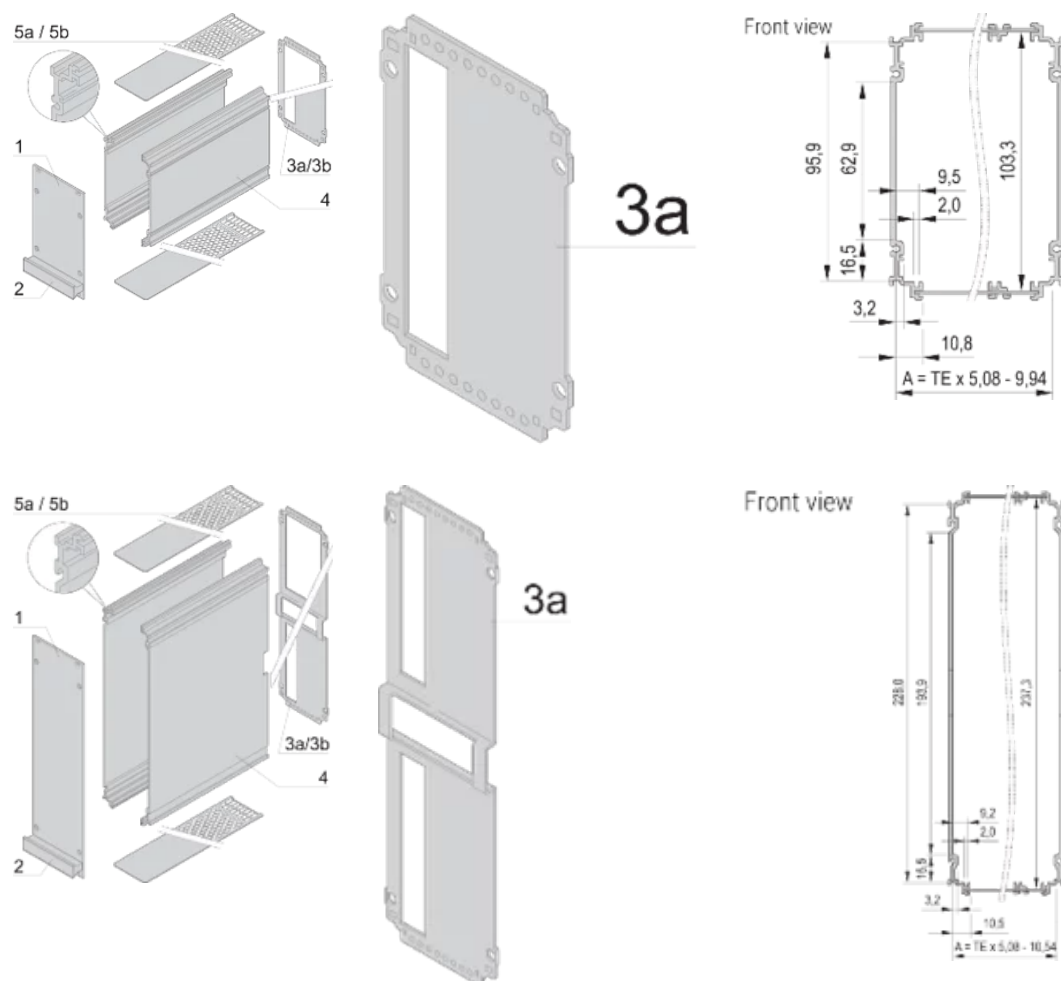

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab  
Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**