




# Набор для монтажа вставных блоков рамного типа PRO, экранированный, перфорированный, 1 разъем, высота 3 U, ширина стойки 12 HP, 167 мм

CATALOG NUMBER



24813-212

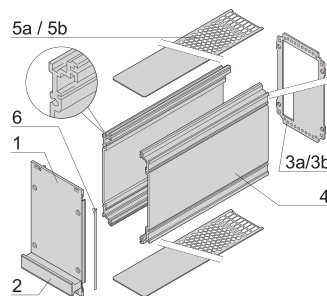

3 U Front panel shieldable

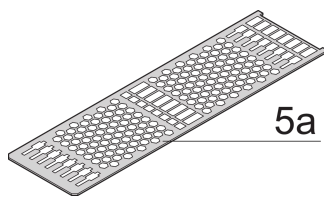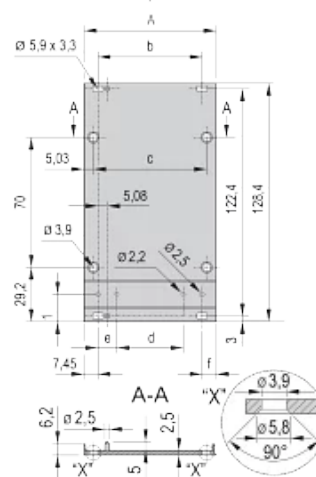

5a

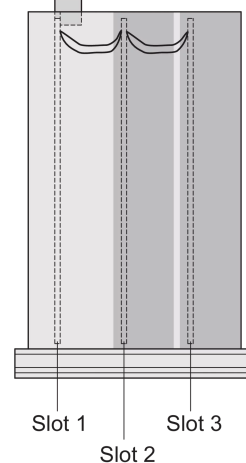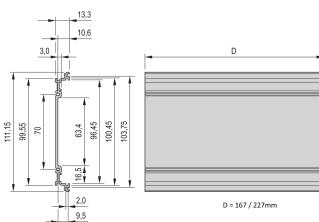

Защищает печатную плату от механических повреждений и электростатического разряда; для европлат; задняя панель с одним вырезом для одного разъема.



## FEATURES

---

Верхняя крышка с перфорацией, для направляющих (воздушный поток приibl. 60 %)

Задняя стенка с выемкой для одного разъема (соответствует EN 60603, DIN 41612, типы конструкции: B, C, D, F, H, Q, R, S)

Экструдированные боковые стенки с пазом справа и слева, для ввода печатной платы (стандартное положение платы только в левой боковой стенке)

## PRODUCT ATTRIBUTES

---

Rack Height: 3U

Rack Width: 12HP

Глубина мм (D): 167mm

Handle Type: Trapezoid

Package Quantity: 1

EMC Gasket Type: Textile

Rear Panel Type: Single Connector Cut-Out

Cover Plate Type: Cover Plate with Perforation for Guide Rails

Front Finish: Anodized

Rear Finish: Conductive

Cooling: C перфорацией

EMC Shielding: Да

Finish: Anodized; Passivated

Material: Алюминий

Product Type: Cassette

Type: Frame Type Plug-in Units PRO


## ADDITIONAL PRODUCT DETAILS

---

Направляющие заказываются отдельно.

To fit further boards without rear connector, guide rail (part no. 24812-301) and 'Board fixing from slot 2' (part no. 24812-301 + screw part no. 24560-178) are required, 2 guide rails, 2 rear panel holders and board fixing for slot 1 and one slot 2 are already included.

## DIAGRAMS

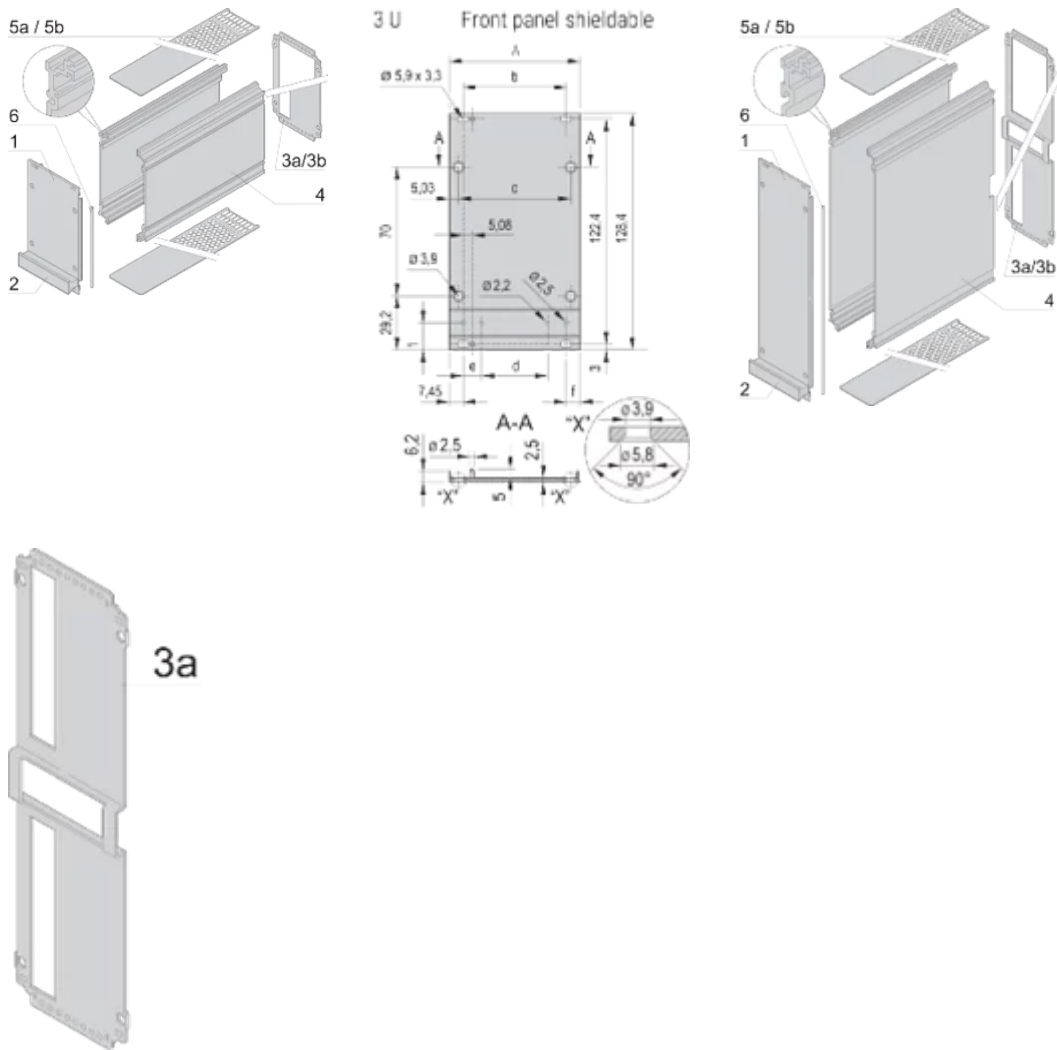

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations

+1.763.422.2661

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

### Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

### Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

### Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**