


**Набор для монтажа вставных блоков  
рамного типа PRO, экранированный,  
перфорированный, 1 разъем, высота 6 U,  
ширина стойки 14 HP, 227 мм**

CATALOG NUMBER

**24813-764**

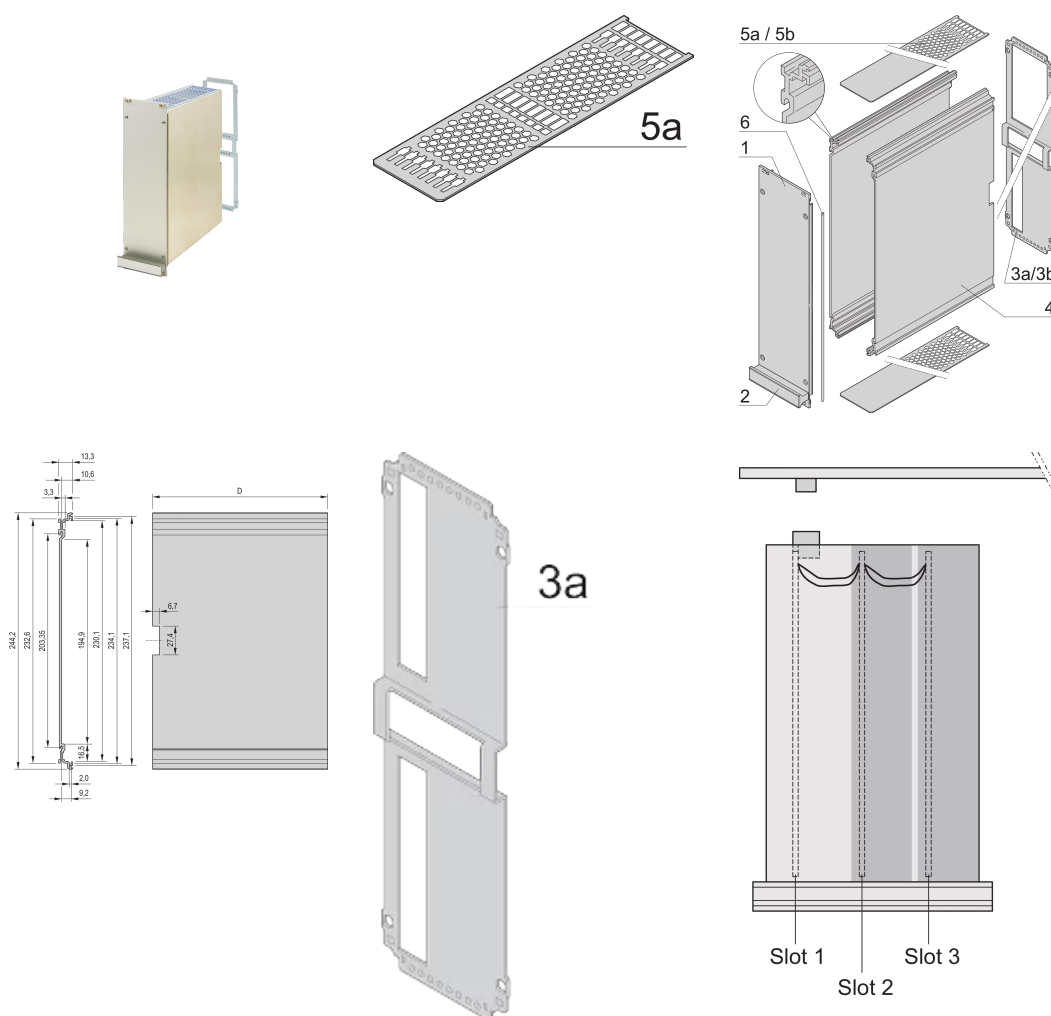

Защищает печатную плату от механических повреждений и электростатического разряда; для европлат; задняя панель с одним вырезом для одного разъема.

## CERTIFICATIONS

---



## FEATURES

---

Верхняя крышка с перфорацией, для направляющих (воздушный поток приibl. 60 %)

Задняя стенка с выемкой для одного разъема (соответствует EN 60603, DIN 41612, типы конструкции: B, C, D, F, H, Q, R, S)

Экструдированные боковые стенки с пазом справа и слева, для ввода печатной платы (стандартное положение платы только в левой боковой стенке)

## PRODUCT ATTRIBUTES

---

Rack Height: 6U

Rack Width: 14HP

Глубина мм (D): 227mm

Handle Type: Trapezoid

Package Quantity: 1

Gasket Type: Textile EMC

Rear Panel Type: Single Connector Cut-Out

Cover Plate Type: Cover Plate with Perforation for Guide Rails

Front Finish: Anodized

Rear Finish: Conductive

Cooling: С перфорацией

EMC Shielding: Да

Finish: Anodized; Passivated

Material: Алюминий

Product Type: Cassette

Type: Frame Type Plug-in Units PRO

Net Weight: 1.23kg

## ADDITIONAL PRODUCT DETAILS

---

Направляющие заказываются отдельно.

To fit further boards without rear connector, guide rail (part no. 24812-301) and 'Board fixing from slot 2' (part no. 24812-301 + screw part no. 24560-178) are required, 2 guide rails, 2 rear panel holders and board fixing for slot 1 and one slot 2 are already included.

DIAGRAMS



WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**