


Задняя панель для высокочастотного вставного модуля рамного типа, с вырезом для одного разъема, 3 U, 10 HP

CATALOG NUMBER

30809-642

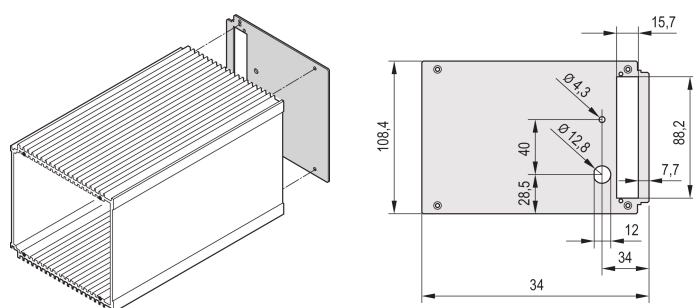

Задняя панель для высокочастотного вставного модуля рамного типа, с вырезом для одного разъема, позволяет пользователю закрепить разъем. В соответствии с EN 60603-2.

CERTIFICATIONS



FEATURES

Задняя панель для высокочастотного вставного модуля рамного типа, с выемкой для одного разъема

PRODUCT ATTRIBUTES

Rack Width: 10HP

Package Quantity: 1

Material: Алюминий

Product Type: Side Panel

Type: Rear Panel

Works With: Frame Type Plug-In Unit

Gross Weight: 0.016kg


ADDITIONAL PRODUCT DETAILS

Обратите внимание, что поставки доступны в указанных стандартных товарных партиях (товарная партия, например, 5 шт., 10 шт., 50 шт. и т. д.). Другие объемы заказов (например, 2 шт.) могут округляться вверх до следующего возможного размера стандартной товарной партии.

Задняя панель для высокочастотных вставных модулей может быть изменена с помощью конфигуратора передней панели.

The cut-outs in the rear Panel suit the following EN 60603 (DIN 41612) connector types: 7 HPB, C, D, R10 - 28 HPB, C, D, R, F, H, MF, MHRear Panels with cut-outs for connectors reduce effectiveness of EMC sealing.

DIAGRAMS

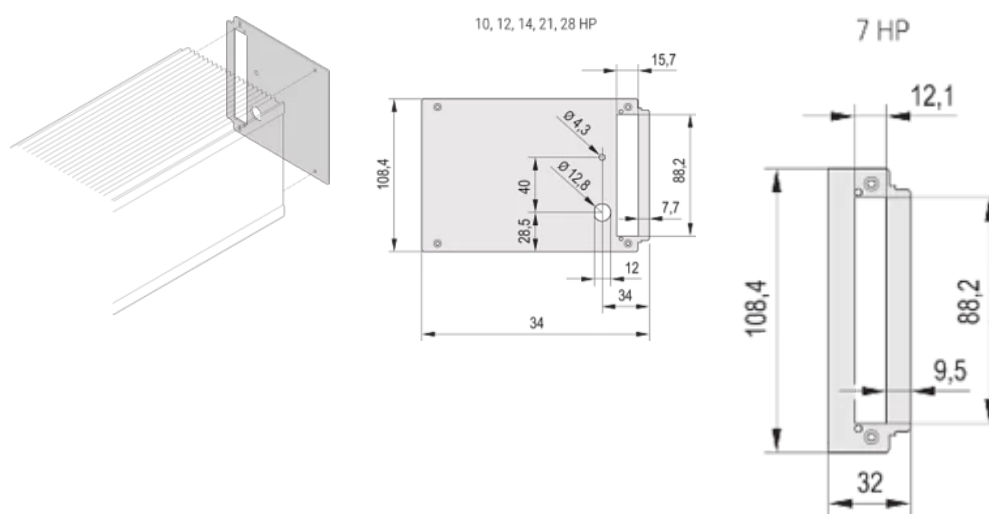

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE