
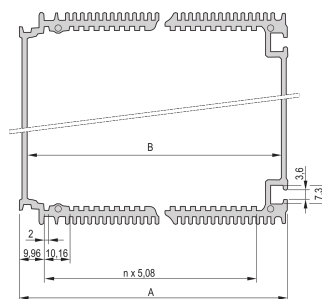
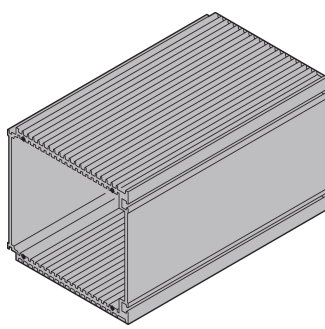


Тубус корпуса для высокочастотного вставного блока рамного типа, 21 HP, для печатной платы глубиной 220 мм

CATALOG NUMBER

30809-672

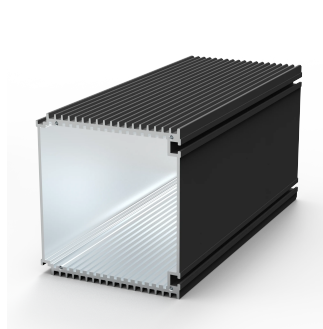

Черный ВЧ-трубчатый корпус для высокочастотного сменного блока рамного типа позволяет пользователю вставлять печатные платы.

CERTIFICATIONS



FEATURES

Черный ВЧ-трубчатый корпус, для высокочастотного сменного блока рамного типа позволяет пользователю вставлять печатные платы

Трубчатый корпус обеспечивает экранирование от высокочастотного излучения

Корпус модуля с охлаждающими ребрами

Вставной модуль может монтироваться в блочном каркасе или крепиться сбоку к монтажной панели с помощью закладной гайки

PRODUCT ATTRIBUTES

Rack Width: 21HP

Package Quantity: 1

Finish: Anodized

Длина мм (L): 227mm

Material: Алюминий

Product Type: Крышка

Rack Height: 3U

Works With: Cassettes

Gross Weight: 0.778kg


PCB Length metric: 220mm

ADDITIONAL PRODUCT DETAILS

Передняя панель, задняя панель, кронштейны для печатных плат и крепежные материалы заказываются отдельно.

Обратите внимание, что поставки доступны в указанных стандартных товарных партиях (товарная партия, например, 5 шт., 10 шт., 50 шт. и т. д.). Другие объемы заказов (например, 2 шт.) могут округляться вверх до следующего возможного размера стандартной товарной партии.

DIAGRAMS

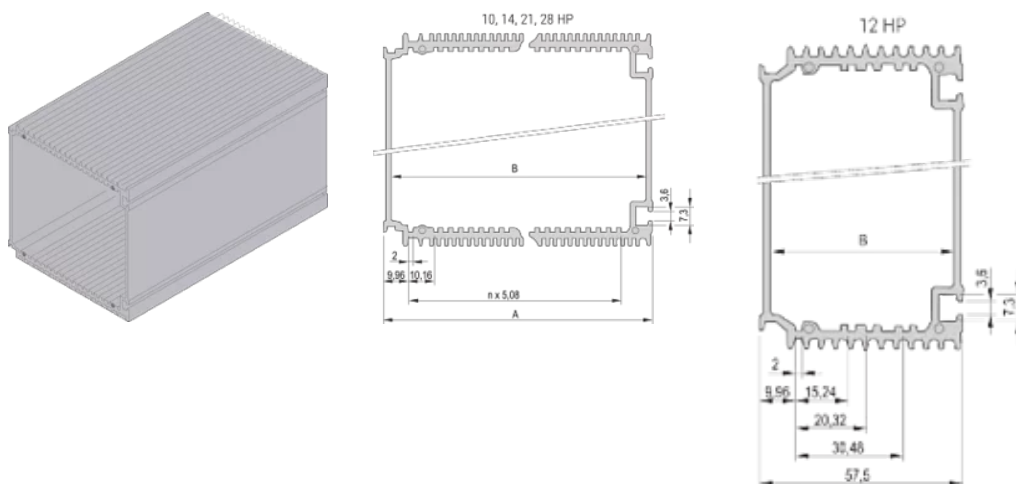

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE