


Горизонтальная рейка, задняя, тип Н-VT, усиленная, 28 НР

CATALOG NUMBER

34560-728

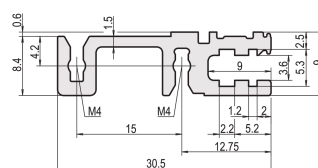

Combinations of horizontal rails and side panels

	"A" can be combined		"A" combination not recommended		
Extruded T		-	+	+	Advised to support
Recessed T		+	Advised to flexibly fix the connection	Advised to flexibly and permanently secure	Advised to support
Extruded L		Advised to fix rigid	Advised to flexibly	-	-
Recessed L		+	+	-	-
Recessed H					
Side panel					
	Light T	Recessed T	Heavy T	Extruded T	

Горизонтальная рейка, тип VT, обеспечивает прямой монтаж объединительной платы.

CERTIFICATIONS



FEATURES

Для прямого монтажа объединительной платы

Установка сверху и снизу

Заглубленный монтаж для высоких механических нагрузок (H-VT)

Алюминиевый экструдированный профиль, анодированная поверхность, электропроводящая контактная поверхность

PRODUCT ATTRIBUTES

Rack Width: 28HP
Package Quantity: 1
Finish: Anodized
Длина мм: 147.32mm
Material: Алюминий
Product Family: EuropacPRO; RatiopacPRO; RatiopacPRO AIR; CompacPRO; PropacPRO
Product Type: Горизонтальный рельс
Type: Heavy, VT
Works With: Блочный каркас; Coffrets
Gross Weight: 0.054kg

ADDITIONAL PRODUCT DETAILS

Поставка исключительно в размере товарной партии. Цена указана за отдельную единицу.

Обратите внимание, что поставки доступны в указанных стандартных товарных партиях (товарная партия, например, 5 шт., 10 шт., 50 шт. и т. д.). Другие объемы заказов (например, 2 шт.) могут округляться вверх до следующего возможного размера стандартной товарной партии.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America All locations +1.763.422.2661 Chat with us: nvent.com/schroff	Europe Straubenhardt, Germany +49.7082.794.0 Betschdorf, France +33.3.88.90.64.90 Warsaw, Poland +48.22.209.98.35 Assago, Italy +39.02.932.7141 Chat with us: nvent.com/schroff	Asia Shanghai, China +86.21.2412.6943 Qingdao, China +86.532.8771.6101 Singapore +65.6768.5800 Shin-Yokohama, Japan +81.45.476.0271 Chat with us: nvent.com/schroff	Middle East & India Dubai, United Arab Emirates +971.4.378.1700 Bangalore, India +91.80.6715.2001 Istanbul, Turkey +90.216.250.7374 Chat with us: nvent.com/schroff
---	---	---	---



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE