


Задний горизонтальный рельс типа АВ для направляющих задних печатных плат ввода/вывода, 40 HP

CATALOG NUMBER

34561-540

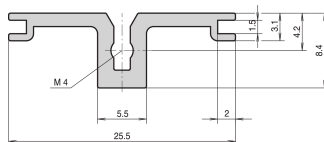

Combinations of horizontal rails and side panels

“+” = can be combined, “-” = combination not recommended

	Light r. L	Standard r. L	Heavy r. L	Rugged r. L
Standard r. R	-	+	+	+
Heavy r. R	+	+	+	+
Light r. R	+	+	-	-
Horizontal rail	+	+	-	-

Light r. L: Light r. R: Standard r. L: Heavy r. L: Rugged r. L: Standard r. R: Heavy r. R: Light r. R: Horizontal rail

Горизонтальная рейка из алюминиевого экструдированного профиля типа АВ (АВ = опора), для задних направляющих ввода/вывода, с анодированной поверхностью и проводящей контактной поверхностью. Подходят для RatiopacPRO/-AIR и EuropacPRO/-rugged).

CERTIFICATIONS



FEATURES

Для CompactPCI в зоне задней панели ввода-вывода

Для расширения 2 × 3 U, требуются 2 горизонтальные рейки типа АВ

Алюминиевый экструдированный профиль, анодированная поверхность, электропроводящая контактная поверхность, с маркировкой HP

PRODUCT ATTRIBUTES

Rack Width: 40HP

Package Quantity: 1

Finish: Anodized

Длина мм: 208.28mm

Material: Алюминий

Product Family: EuropacPRO; RatiopacPRO; RatiopacPRO AIR; CompacPRO; PropacPRO

Product Type: Горизонтальный рельс

Type: Type AB

Works With: Блочный каркас; Coffrets

Gross Weight: 0.035kg

ADDITIONAL PRODUCT DETAILS

Поставка исключительно в размере товарной партии. Цена указана за отдельную единицу.

Обратите внимание, что поставки доступны в указанных стандартных товарных партиях (товарная партия, например, 5 шт., 10 шт., 50 шт. и т. д.). Другие объемы заказов (например, 2 шт.) могут округляться вверх до следующего возможного размера стандартной товарной партии.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:

nvent.com/schroff



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE