


Монтажная панель для 19-дюймового корпуса и блочного каркаса, 84 HP, длина печатной платы 220 мм

CATALOG NUMBER

34562-752

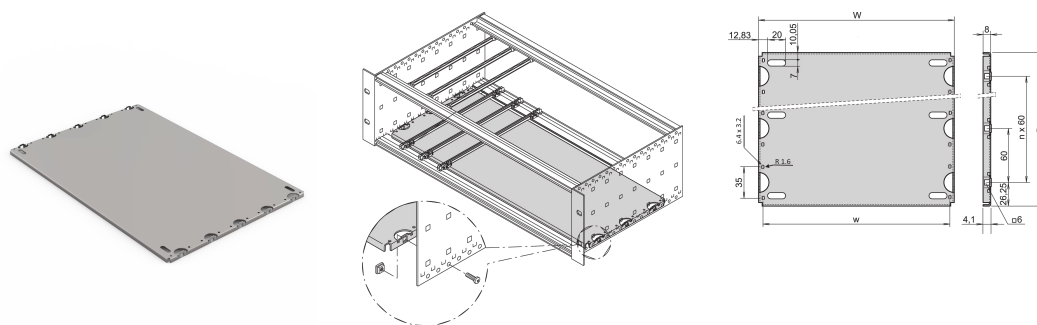

Material	HP	W	w	D
34562745	28	146,87	137,16	112,50
34562749	28	146,87	137,16	172,50
34562753	28	146,87	137,16	232,50
34562757	28	146,87	137,16	292,50
34562746	42	217,99	208,28	112,50
34562750	42	217,99	208,28	172,50
34562754	42	217,99	208,28	232,50
34562758	42	217,99	208,28	292,50
34562747	63	324,67	314,96	112,50
34562751	63	324,67	314,96	172,50
34562755	63	324,67	314,96	232,50
34562759	63	324,67	314,96	292,50
34562748	84	431,35	421,64	112,50
34562752	84	431,35	421,64	172,50
34562756	84	431,35	421,64	232,50
34562760	84	431,35	421,64	292,50
34562870	84	431,35	421,64	352,50
34562871	84	431,35	421,64	412,50

Монтажная панель для тяжелых компонентов или запатентованных электронных блоков. Подходит для RatiopacPRO/-AIR, CompacPRO и EuropacPRO.

Направляющие типа 4,4-дюймовые и усиленные не могут использоваться в сочетании с монтажной панелью. Верхняя/нижняя крышка, которая будет вставлена в паз легких горизонтальных реек (тип L), не может использоваться в сочетании с монтажной панелью.

CERTIFICATIONS



FEATURES

Для крепления тяжелых компонентов

Монтажная плата, полная ширина: Монтажная панель имеет такую же ширину, как и блочный каркас, и крепится к боковым стенкам

Монтажная плата, частичная ширина: Монтажная панель частичной ширины, прикрепленная к боковой панели с помощью монтажной планки

The chassis plate can't be combined with EMC top- / bottom covers

PRODUCT ATTRIBUTES

Rack Width: 84HP

Package Quantity: 1

Глубина мм: 172.5mm

Material: Алюминий

Product Family: EuropacPRO; CompacPRO; RatiopacPRO; PropacPRO

Product Type: Монтажная панель

Ширина мм: 431.35mm

Works With: Блочный каркас

Net Weight: 0.37kg

ADDITIONAL PRODUCT DETAILS

Монтажный комплект для монтажной панели заказывается отдельно.

Другие варианты исполнения по запросу.

Крепежные планки, необходимые для панелей неполной ширины, заказываются отдельно.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE