


Монтажная панель EurorasPRO для использования с заглушкой, ширина стойки 84 HP, длина панели 160 мм

CATALOG NUMBER

34563-004

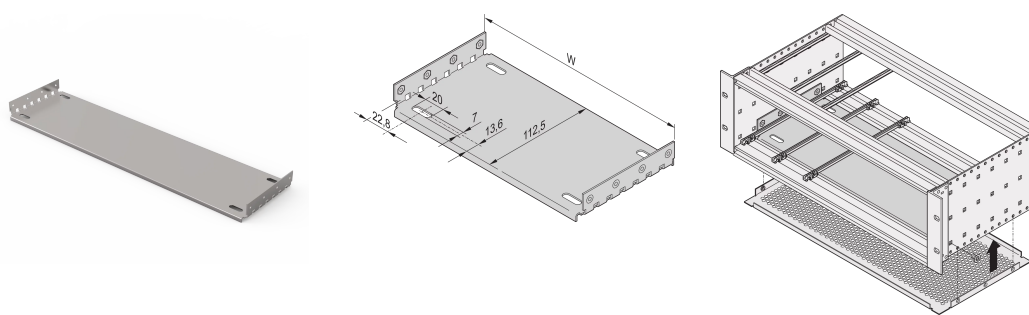

Material	HP	W	D
34563001	28	146,87	112,50
34563009	28	146,87	172,50
34563002	42	217,99	112,50
34563014	42	217,99	172,50
34563003	63	324,67	112,50
34563019	63	324,67	172,50
34563004	84	431,35	112,50
34563024	84	431,35	172,50
34563026	84	431,35	232,50
34563028	84	431,35	292,50
34563042	84	431,35	352,50
34563044	84	431,35	412,50

Монтажная панель для использования с заглушками для установки и крепления тяжелых компонентов. Монтажные панели полной ширины (как и блочный каркас или системный корпус) крепятся к боковым стенкам. Монтажные панели парциальной ширины крепятся к боковой панели и горизонтальной рейке с помощью монтажной рейки.

Направляющие типа 4,4-дюймовые и усиленные не могут использоваться в сочетании с монтажной панелью. Верхняя/нижняя крышка, которая будет вставлена в паз легких горизонтальных реек (тип L), не может использоваться в сочетании с монтажной панелью.

CERTIFICATIONS



FEATURES

Для установки и крепления тяжелых компонентов

Монтажная плата, полная ширина: Монтажная панель имеет такую же ширину, как и блочный каркас, и крепится к боковым стенкам

Возможен монтаж направляющих в первый и последний слот

Помимо монтажной панели на блочном каркасе могут быть также установлены ЭМС-крышки

Нельзя использовать направляющие типа 4,4 и «усиленные» направляющие

Возможен монтаж направляющих в первый и последний слот

PRODUCT ATTRIBUTES

Rack Width: 84HP

Package Quantity: 1

Глубина мм: 112.5mm

Material: Алюминий

Product Family: EuropacPRO

Product Type: Монтажная панель

Ширина мм: 431.35mm

Works With: Блочный каркас

Net Weight: 0.23kg

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE