


Металлокерамический потенциометр, 100 кОм

CATALOG NUMBER

69004-155

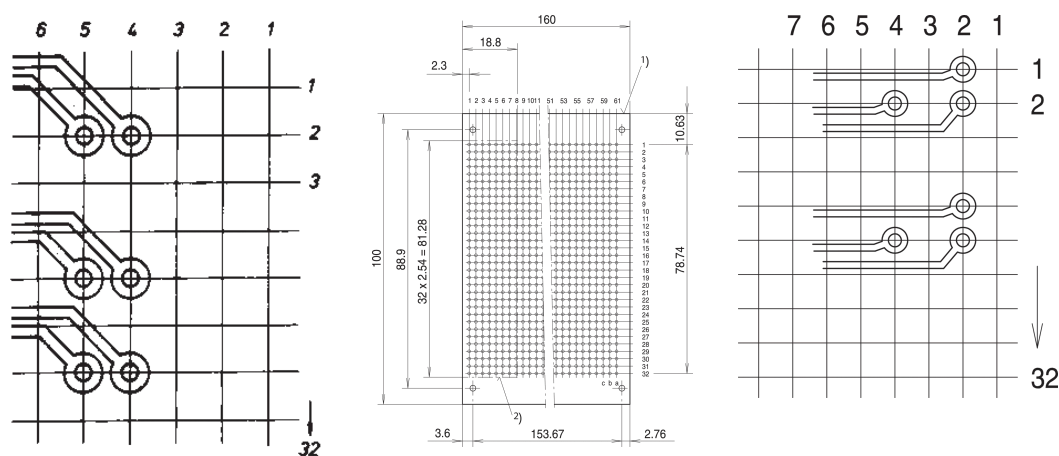

Потенциометр – это электрический компонент сопротивления, значения которого могут быть изменены механически (путем поворота или сдвига).

CERTIFICATIONS



FEATURES

Укороченная конструктивная форма для монтажной плоскости 1

PRODUCT ATTRIBUTES

Product Type: Потенциометр

Сопротивление Ω : 100000 Ω

Package Quantity: 1

ADDITIONAL PRODUCT DETAILS

Dimensions of connecting pins: 0,45 × 0,45 mm.

Обратите внимание, что поставки доступны в указанных стандартных товарных партиях (товарная партия, например, 5 шт., 10 шт., 50 шт. и т. д.). Другие объемы заказов (например, 2 шт.) могут округляться вверх до следующего возможного размера стандартной товарной партии.

Required front panel drill hole: Ø 8 mm.

When left-hinged: pins 1 and 2 low-ohmic.

When right-hinged: pins 2 and 3 low-ohmic.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE