


# EuropacPRO Rugged Rear Angle for Textile EMC Gasket

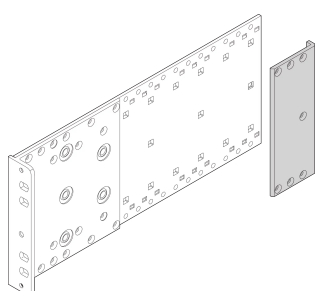

Угловой профиль закрывает слот между боковой панелью и задней панелью блочного каркаса. Необходим для надлежащего ЭМС-экранирования.

## CERTIFICATIONS



## FEATURES

Требуется для экранирования задней стороны

Также возможно применение в качестве элемента передней облицовки при использовании с 19" кронштейна с регулируемой глубиной установки

## SPECIFICATIONS

|                        |                |
|------------------------|----------------|
| <b>Material:</b>       | Алюминий       |
| <b>Product Type:</b>   | Крышка         |
| <b>Product Family:</b> | EuropacPRO     |
| <b>Type:</b>           | Rugged         |
| <b>Works With:</b>     | Блочный каркас |

Table 1/2

| Catalog Number | Rack Height | Design Feature | Package Quantity | Высота мм | Package Unit | Certifications |
|----------------|-------------|----------------|------------------|-----------|--------------|----------------|
| 24566-497      | 6U          | CPCI           | 2                | 265.9mm   | Pair         |                |

| CatalogNumber | Rack Height | Design Feature | Package Quantity | Высота мм | Package Unit | Certifications |
|---------------|-------------|----------------|------------------|-----------|--------------|----------------|
| 24566-197     | 3U          | CPCI           | 2                | 132.6mm   | Pair         |                |
| 24566-199     | 3U          |                | 2                | 132.6mm   | Pair         | RoHS           |
| 24566-499     | 6U          |                | 2                | 265.9mm   | Pair         | RoHS           |

Table 2/2

| Catalog Number | Quick Ship |
|----------------|------------|
| 24566-497      | No         |
| 24566-197      | No         |
| 24566-199      | No         |
| 24566-499      | No         |

## ADDITIONAL PRODUCT DETAILS

Текстильный уплотнитель ЭМС заказывается отдельно.

Угловой профиль не используется с адаптером для крепления с обратной стороны.

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**