


# 19-дюймовый каркас Eurorack

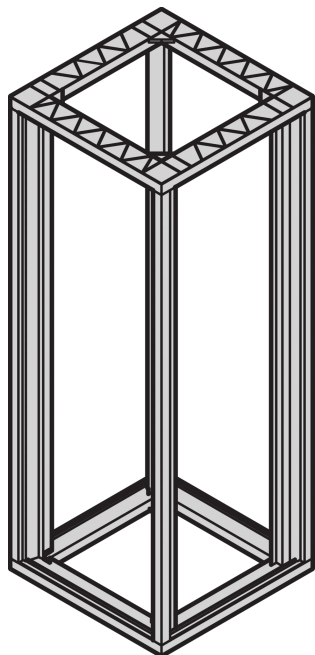

Фиксированное расстояние между передней и задней 19-дюймовыми панелями

## CERTIFICATIONS



## FEATURES

На винтах, рама из алюминия (литье под давлением), стойки из алюминиевого профиля

Фиксированное расстояние между передним и задним 19" монтажным уровнем

Поверхность: RAL 7021

## SPECIFICATIONS

|                        |                    |
|------------------------|--------------------|
| <b>Static Load:</b>    | 400kg              |
| <b>Frame Material:</b> | Алюминий           |
| <b>Material:</b>       | Алюминий           |
| <b>Product Type:</b>   | Cabinet/Rack Frame |

Table 1/2

| Catalog Number | Rack Height | Высота мм | Ширина мм | Глубина мм | Package Quantity | Color      |
|----------------|-------------|-----------|-----------|------------|------------------|------------|
| 22117-772      | 34U         | 1620mm    | 600mm     | 600mm      | 1                | Black Grey |
| 22117-773      | 34U         | 1620mm    | 600mm     | 800mm      | 1                | Black Grey |
| 22117-774      | 34U         | 1620mm    | 600mm     | 900mm      | 1                | Black Grey |
| 22117-775      | 38U         | 1798mm    | 600mm     | 600mm      | 1                | Black Grey |
| 22117-776      | 38U         | 1798mm    | 600mm     | 800mm      | 1                | Black Grey |
| 22117-777      | 38U         | 1798mm    | 600mm     | 900mm      | 1                | Black Grey |
| 22117-778      | 43U         | 2020mm    | 600mm     | 600mm      | 1                | Black Grey |
| 22117-779      | 43U         | 2020mm    | 600mm     | 800mm      | 1                | Black Grey |
| 22117-780      | 43U         | 2020mm    | 600mm     | 900mm      | 1                | Black Grey |
| 22117-781      | 47U         | 2198mm    | 600mm     | 800mm      | 1                | Black Grey |
| 22117-977      | 20U         | 998mm     | 600mm     | 600mm      | 1                | Black Grey |
| 22117-978      | 20U         | 998mm     | 600mm     | 800mm      | 1                | Black Grey |
| 22117-979      | 25U         | 1220mm    | 600mm     | 600mm      | 1                | Black Grey |
| 22117-980      | 25U         | 1220mm    | 600mm     | 800mm      | 1                | Black Grey |
| 22117-981      | 29U         | 1398mm    | 600mm     | 600mm      | 1                | Black Grey |
| 22117-982      | 29U         | 1398mm    | 600mm     | 800mm      | 1                | Black Grey |
| 22117-983      | 47U         | 2198mm    | 600mm     | 600mm      | 1                | Black Grey |
| 22117-984      | 47U         | 2198mm    | 600mm     | 900mm      | 1                | Black Grey |

Table 2/2

| Catalog Number | Color Code | Finish        | Type     | Quick Ship |
|----------------|------------|---------------|----------|------------|
| 22117-772      | RAL 7021   | Powder Coated | Standard | No         |
| 22117-773      | RAL 7021   | Powder Coated | Standard | No         |
| 22117-774      | RAL 7021   | Powder Coated | Standard | No         |
| 22117-775      | RAL 7021   | Powder Coated | Standard | No         |
| 22117-776      | RAL 7021   | Powder Coated | Standard | No         |
| 22117-777      | RAL 7021   | Powder Coated | Standard | No         |
| 22117-778      | RAL 7021   | Powder Coated | Standard | No         |
| 22117-779      | RAL 7021   | Powder Coated | Standard | No         |
| 22117-780      | RAL 7021   | Powder Coated | Standard | No         |
| 22117-781      | RAL 7021   | Powder Coated | Standard | No         |
| 22117-977      | RAL 7021   | Powder Coated | Standard | No         |
| 22117-978      | RAL 7021   | Powder Coated | Standard | No         |
| 22117-979      | RAL 7021   | Powder Coated | Standard | No         |
| 22117-980      | RAL 7021   | Powder Coated | Standard | No         |
| 22117-981      | RAL 7021   | Powder Coated | Standard | No         |
| 22117-982      | RAL 7021   | Powder Coated | Standard | No         |
| 22117-983      | RAL 7021   | Powder Coated | Standard | No         |
| 22117-984      | RAL 7021   | Powder Coated | Standard | No         |

**WARNING**

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

**North America**

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

**Europe**

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

**Asia**

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

**Middle East & India**

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**