


Направляющие рельсы Eurorack, 25 кг

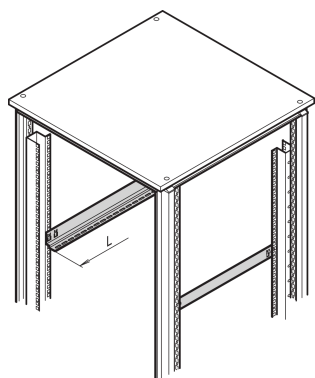

Направляющий рельс Eurorack с нагрузочной способностью 25 кг для монтажа в стойках шкафа или на 19-дюймовых креплениях для панелей/направляющих. Направляющий рельс поддерживает полку тяжелых 19-дюймовых шасси.

CERTIFICATIONS



FEATURES

сталь, 1,5 мм, покрытие алюцинк

Допустимая статическая нагрузка 25 кг на пару

Опоры для тяжелого 19" шасси

Для монтажа требуются четыре 19" монтажных профиля

Широкая поверхность опоры

Навеска с шагом 1 U

SPECIFICATIONS

Static Load: 25kg

Product Type: Slide Rail

Material: Сталь

Table 1/1

Catalog Number	Глубина мм	Длина мм	Package Quantity	Finish	Quick Ship
----------------	------------	----------	------------------	--------	------------

22127-094	600mm	420mm	2	Aluminum-Zinc Plated	No
25127-575	800mm	512mm	2	Aluminum-Zinc Plated	No
22127-095	800mm	620mm	2	Aluminum-Zinc Plated	No
22127-096	900mm	717mm	2	Aluminum-Zinc Plated	No
21127-197	600mm	420mm	10	Aluminum-Zinc Plated	No
21127-198	800mm	620mm	10	Aluminum-Zinc Plated	No
21127-199	900mm	720mm	10	Aluminum-Zinc Plated	No

ADDITIONAL PRODUCT DETAILS

Стандартное расстояние для серверов d = 740 мм. Для сборки требуется 4 штук креплений для панелей/направляющих (заказываются отдельно, см. информацию о креплениях для панелей/направляющих).

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE