


передняя панель, полная ширина, с простым шлицем, Без экранирования, for RatiopacPRO

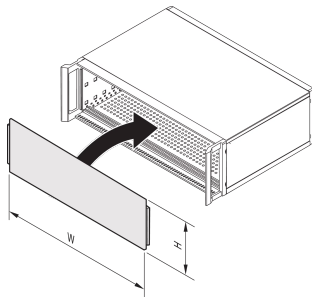

Полноразмерная, с прорезями, неэкранированная передняя панель для RatiopacPRO/-AIR.

CERTIFICATIONS



FEATURES

Вставлена между боковой панелью и формованными деталями, 19-дюймовый монтажный кронштейн или ручка

Передние панели также могут использоваться в качестве задних панелей

Фиксирует без винтов (специальные горизонтальные рейки покрывают края передней панели и удерживают их на месте).

Экранированная (проводящая сзади); для проводящего соединения с корпусом нужно отдельно заказать ЭМС-уплотнение (нержавеющая сталь)

SPECIFICATIONS

Глубина мм (D):	2.5mm
Material:	Алюминий
Finish:	Anodized; Passivated
Аксессуар Тип:	Передняя панель
Product Type:	Передняя панель

Table 1/2

Catalog Number	Rack Height	Rack Width	Package Quantity	Front Finish	Rear Finish	Treated Edges
34571-617	2U	28HP	1	Anodized	Conductive	Her
34571-618	2U	42HP	1	Anodized	Conductive	Her
34571-605	3U	28HP	1	Anodized	Conductive	Her
34571-609	4U	28HP	1	Anodized	Conductive	Her
34571-606	3U	42HP	1	Anodized	Conductive	Her
34571-619	2U	63HP	1	Anodized	Conductive	Her
34571-621	5U	28HP	1	Anodized	Conductive	Her
34571-620	2U	84HP	1	Anodized	Conductive	Her
34571-610	4U	42HP	1	Anodized	Conductive	Her
34571-613	6U	28HP	1	Anodized	Conductive	Her
34571-607	3U	63HP	1	Anodized	Conductive	Her
34571-622	5U	42HP	1	Anodized	Conductive	Her
34571-608	3U	84HP	1	Anodized	Conductive	Her
34571-611	4U	63HP	1	Anodized	Conductive	Her
34571-614	6U	42HP	1	Anodized	Conductive	Her
34571-623	5U	63HP	1	Anodized	Conductive	Her
34571-612	4U	84HP	1	Anodized	Conductive	Her
34571-615	6U	63HP	1	Anodized	Conductive	Her


CatalogNumber	Rack Height	Rack Width	Package Quantity	Front Finish	Rear Finish	Treated Edges
34571-624	5U	84HP	1	Anodized	Conductive	Нет
34571-616	6U	84HP	1	Anodized	Conductive	Нет

Table 2/2

Catalog Number	Высота мм (H)	Ширина мм (W)	Quick Ship
34571-617	84mm	141.9mm	No
34571-618	84mm	213.2mm	No
34571-605	128.4mm	141.9mm	No
34571-609	172.9mm	141.9mm	No
34571-606	128.4mm	213.2mm	No
34571-619	84mm	319.7mm	No
34571-621	217.3mm	141.9mm	No
34571-620	84mm	426.4mm	No
34571-610	172.9mm	213.2mm	No
34571-613	261.8mm	141.9mm	No
34571-607	128.4mm	319.7mm	No
34571-622	217.3mm	213.2mm	No
34571-608	128.4mm	426.4mm	No
34571-611	172.9mm	319.7mm	No
34571-614	261.8mm	213.2mm	No

Catalog Number	Высота мм (H)	Ширина мм (W)	Quick Ship
34571-623	217.3mm	319.7mm	No
34571-612	172.9mm	426.4mm	No
34571-615	261.8mm	319.7mm	No
34571-624	217.3mm	426.4mm	No
34571-616	261.8mm	426.4mm	No

DIAGRAMS

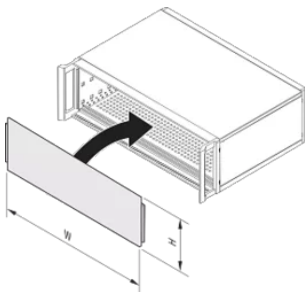

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE