


Guide Rail Multi Piece, Mid-Piece Aluminium/Plastic Extrusion

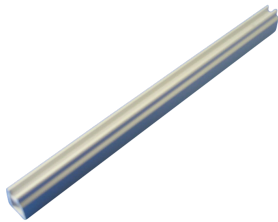

FEATURES

Middle profile for mounting guide rails for 2.5 mm groove width

2 plastic end pieces are required; these are pushed on to both ends of the middle profile

Guide rails can be clipped into horizontal rails (Al extrusion) or into 1.5 mm thick plates

Storage temperature: from -40 °C ... 130 °C

SPECIFICATIONS

Table 1/2

Catalog Number	Board Depth	Color	Finish	Groove Width	Material	Package Quantity
34562-822	1000mm	Серебристый	Anodized	2.5	Алюминий	1
34562-814	220mm	Серебристый	Anodized	2.5	Алюминий	1
34562-815	280mm	Серебристый	Anodized	2.5	Алюминий	1
34562-813	160mm	Серебристый	Anodized	2.5	Алюминий	1
34562-816	340mm	Серебристый	Anodized	2.5	Алюминий	1

Table 2/2

Catalog Number	Type	Works With	Quick Ship
34562-822	Middle Section	Блочный каркас, Coffrets, Chassis	No
34562-814	Middle Section	Блочный каркас, Coffrets, Chassis	No
34562-815	Middle Section	Блочный каркас, Coffrets, Chassis	No
34562-813	Middle Section	Блочный каркас, Coffrets, Chassis	No
34562-816	Middle Section	Блочный каркас, Coffrets, Chassis	No

ADDITIONAL PRODUCT DETAILS

Delivery may be in Standard Pack Quantity (SPQ). Pricing is per individual item.

One guide rail consists of 1 pair of head pieces and 1 profile piece.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE