


Монтажная панель для 19-дюймового корпуса и блочного каркаса

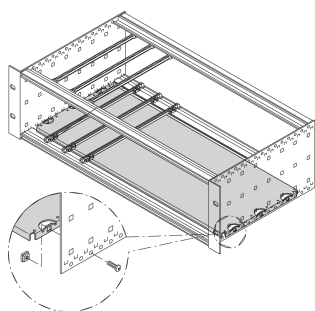

Монтажная панель для тяжелых компонентов или запатентованных электронных блоков. Подходит для RatiopacPRO/-AIR, CompacPRO и EuropacPRO.

Направляющие типа 4,4-дюймовые и усиленные не могут использоваться в сочетании с монтажной панелью. Верхняя/нижняя крышка, которая будет вставлена в паз легких горизонтальных реек (тип L), не может использоваться в сочетании с монтажной панелью.

CERTIFICATIONS



FEATURES

Для крепления тяжелых компонентов

Монтажная плата, полная ширина: Монтажная панель имеет такую же ширину, как и блочный каркас, и крепится к боковым стенкам

Монтажная плата, частичная ширина: Монтажная панель частичной ширины, прикрепленная к боковой панели с помощью монтажной планки

The chassis plate can't be combined with EMC top- / bottom covers

SPECIFICATIONS

Material:	Алюминий
Product Type:	Монтажная панель
Works With:	Блочный каркас

Table 1/2

Catalog Number	Rack Width	Package Quantity	Глубина мм	Product Family	Ширина мм	Certifications
----------------	------------	------------------	------------	----------------	-----------	----------------

34562-745	28HP	1	112.5mm	EuropacPRO, RatiopacPRO, CompacPRO	146.88mm	RoHS
34562-749	28HP	1	172.5mm	EuropacPRO, RatiopacPRO, CompacPRO	146.88mm	RoHS
34562-746	42HP	1	112.5mm	EuropacPRO, PropacPRO, RatiopacPRO, CompacPRO	217.99mm	RoHS
34562-753	28HP	1	232.5mm	EuropacPRO, RatiopacPRO, CompacPRO	146.88mm	RoHS
34562-757	28HP	1	292.2mm	EuropacPRO, RatiopacPRO, CompacPRO	146.88mm	RoHS
34562-747	63HP	1	112.5mm	EuropacPRO, PropacPRO, RatiopacPRO, CompacPRO	324.67mm	RoHS
34562-750	42HP	1	172.5mm	EuropacPRO, CompacPRO, RatiopacPRO, PropacPRO	217.99mm	RoHS
34562-748	84HP	1	112.5mm	EuropacPRO, PropacPRO, RatiopacPRO, CompacPRO	324.67mm	RoHS
34562-754	42HP	1	232.5mm	EuropacPRO, RatiopacPRO, CompacPRO	217.99mm	RoHS
34562-751	63HP	1	172.5mm	EuropacPRO, RatiopacPRO, CompacPRO, PropacPRO	324.67mm	RoHS
34562-758	42HP	1	292.2mm	EuropacPRO, RatiopacPRO, CompacPRO	217.99mm	RoHS
34562-752	84HP	1	172.5mm	EuropacPRO, CompacPRO, RatiopacPRO, PropacPRO	431.35mm	RoHS
34562-755	63HP	1	232.5mm	EuropacPRO, RatiopacPRO, CompacPRO	324.67mm	RoHS

34562-759	63HP	1	292.2mm	EuropacPRO, RatiopacPRO, CompacPRO	324.67mm	RoHS
34562-756	84HP	1	232.5mm	EuropacPRO, RatiopacPRO, CompacPRO	431.35mm	RoHS
34562-760	84HP	1	292.5mm	EuropacPRO, PropacPRO, RatiopacPRO, CompacPRO	431.35mm	RoHS
34562-870	84HP	1	352.5mm	EuropacPRO	431.35mm	
34562-871	84HP	1	412.5mm	EuropacPRO	431.35mm	

Table 2/2	
Catalog Number	Quick Ship
34562-745	No
34562-749	No
34562-746	No
34562-753	No
34562-757	No
34562-747	No
34562-750	No
34562-748	No
34562-754	No
34562-751	No
34562-758	No

Catalog Number	Quick Ship
34562-752	No
34562-755	No
34562-759	No
34562-756	No
34562-760	No
34562-870	No
34562-871	No

ADDITIONAL PRODUCT DETAILS

Монтажный комплект для монтажной панели заказывается отдельно.

Другие варианты исполнения по запросу.

Крепежные планки, необходимые для панелей неполной ширины, заказываются отдельно.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE