


Рама Novastar, Slim-Line

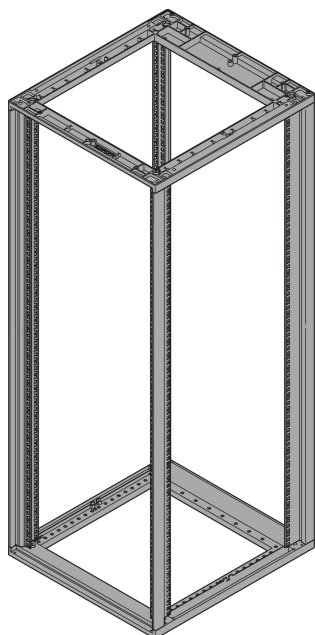

Эстетичная алюминиевая литая рама со статической нагрузкой 200 кг. 19-дюймовая стойка из экструдированного алюминия, прикрученная болтами к рамам.

CERTIFICATIONS



FEATURES

Допустимая статическая нагрузка 200 кг

19-дюймовый монтажный уровень - 33 мм спереди, 60 мм сзади

алюминиевый профиль, RAL 7021, включая заземление

SPECIFICATIONS

Static Load:	200kg
Frame Material:	Алюминий
Material:	Алюминий
Product Type:	Cabinet/Rack Frame

Table 1/2

Catalog Number	Rack Height	Высота мм	Ширина мм	Глубина мм	Package Quantity	Color
28230-001	6U	323mm	553mm	500mm	1	Black Grey
28230-004	9U	456mm	553mm	500mm	1	Black Grey
28230-007	12U	589mm	553mm	500mm	1	Black Grey
28230-011	16U	767mm	553mm	500mm	1	Black Grey
28230-015	20U	945mm	553mm	500mm	1	Black Grey
28230-020	25U	1167mm	553mm	500mm	1	Black Grey
28230-029	34U	1567mm	553mm	500mm	1	Black Grey
28230-033	38U	1745mm	553mm	500mm	1	Black Grey
28230-042	47U	2145mm	553mm	500mm	1	Black Grey
28230-048	43U	1967mm	553mm	500mm	1	Black Grey
28230-054	12U	589mm	553mm	900mm	1	Black Grey
28230-055	12U	589mm	553mm	1000mm	1	Black Grey
28230-060	6U	323mm	553mm	600mm	1	Black Grey
28230-063	9U	456mm	553mm	600mm	1	Black Grey
28230-066	12U	589mm	553mm	600mm	1	Black Grey
28230-070	16U	767mm	553mm	600mm	1	Black Grey
28230-074	20U	945mm	553mm	600mm	1	Black Grey
28230-079	25U	1167mm	553mm	600mm	1	Black Grey

CatalogNumber	Rack Height	Высота мм	Ширина мм	Глубина мм	Package Quantity	Color
28230-088	34U	1567mm	553mm	600mm	1	Black Grey
28230-092	38U	1745mm	553mm	600mm	1	Black Grey
28230-097	43U	1967mm	553mm	600mm	1	Black Grey
28230-101	47U	2145mm	553mm	600mm	1	Black Grey
28230-126	12U	589mm	553mm	800mm	1	Black Grey
28230-130	16U	767mm	553mm	800mm	1	Black Grey
28230-134	20U	945mm	553mm	800mm	1	Black Grey
28230-139	25U	1167mm	553mm	800mm	1	Black Grey
28230-148	34U	1567mm	553mm	800mm	1	Black Grey
28230-152	38U	1745mm	553mm	800mm	1	Black Grey
28230-157	43U	1967mm	553mm	800mm	1	Black Grey
28230-162	47U	2145mm	553mm	800mm	1	Black Grey
28230-190	16U	767mm	553mm	900mm	1	Black Grey
28230-191	16U	767mm	553mm	1000mm	1	Black Grey
28230-194	20U	945mm	553mm	900mm	1	Black Grey
28230-195	20U	945mm	553mm	1000mm	1	Black Grey
28230-198	25U	1167mm	553mm	900mm	1	Black Grey
28230-199	25U	1167mm	553mm	1000mm	1	Black Grey

CatalogNumber	Rack Height	Высота мм	Ширина мм	Глубина мм	Package Quantity	Color
28230-202	34U	1567mm	553mm	900mm	1	Black Grey
28230-203	34U	1567mm	553mm	1000mm	1	Black Grey
28230-206	38U	1745mm	553mm	900mm	1	Black Grey
28230-207	38U	1745mm	553mm	1000mm	1	Black Grey
28230-210	43U	1967mm	553mm	900mm	1	Black Grey
28230-211	43U	1967mm	553mm	1000mm	1	Black Grey
28230-214	47U	2145mm	553mm	900mm	1	Black Grey
28230-215	47U	2145mm	553mm	1000mm	1	Black Grey
28230-024	29U	1345mm	553mm	500mm	1	Black Grey
28230-083	29U	1345mm	553mm	600mm	1	Black Grey
28230-143	29U	1345mm	553mm	800mm	1	Black Grey
28230-218	29U	1345mm	553mm	1000mm	1	Black Grey
28230-226	29U	1345mm	553mm	900mm	1	Black Grey

Table 2/2

Catalog Number	Color Code	Finish	Type	Certifications	Quick Ship
28230-001	RAL 7021	Powder Coated	Slim-Line	RoHS	No
28230-004	RAL 7021	Powder Coated	Slim-Line	RoHS	No
28230-007	RAL 7021	Powder Coated	Slim-Line	RoHS	No
28230-011	RAL 7021	Powder Coated	Slim-Line	RoHS	No

Catalog Number	Color Code	Finish	Type	Certifications	Quick Ship
28230-015	RAL 7021	Powder Coated	Slim-Line	RoHS	No
28230-020	RAL 7021	Powder Coated	Slim-Line	RoHS	No
28230-029	RAL 7021	Powder Coated	Slim-Line	RoHS	No
28230-033	RAL 7021	Powder Coated	Slim-Line	RoHS	No
28230-042	RAL 7021	Powder Coated	Slim-Line	RoHS	No
28230-048	RAL 7021	Powder Coated	Slim-Line	RoHS	No
28230-054	RAL 7021	Powder Coated	Slim-Line	RoHS	No
28230-055	RAL 7021	Powder Coated	Slim-Line	RoHS	No
28230-060	RAL 7021	Powder Coated	Slim-Line	RoHS	No
28230-063	RAL 7021	Powder Coated	Slim-Line	RoHS	No
28230-066	RAL 7021	Powder Coated	Slim-Line	RoHS	No
28230-070	RAL 7021	Powder Coated	Slim-Line	RoHS	No
28230-074	RAL 7021	Powder Coated	Slim-Line	RoHS	No
28230-079	RAL 7021	Powder Coated	Slim-Line	RoHS	No
28230-088	RAL 7021	Powder Coated	Slim-Line	RoHS	No
28230-092	RAL 7021	Powder Coated	Slim-Line	RoHS	No
28230-097	RAL 7021	Powder Coated	Slim-Line	RoHS	No
28230-101	RAL 7021	Powder Coated	Slim-Line	RoHS	No

Catalog Number	Color Code	Finish	Type	Certifications	Quick Ship
28230-126	RAL 7021	Powder Coated	Slim-Line	RoHS	No
28230-130	RAL 7021	Powder Coated	Slim-Line	RoHS	No
28230-134	RAL 7021	Powder Coated	Slim-Line	RoHS	No
28230-139	RAL 7021	Powder Coated	Slim-Line	RoHS	No
28230-148	RAL 7021	Powder Coated	Slim-Line	RoHS	No
28230-152	RAL 7021	Powder Coated	Slim-Line	RoHS	No
28230-157	RAL 7021	Powder Coated	Slim-Line	RoHS	No
28230-162	RAL 7021	Powder Coated	Slim-Line	RoHS	No
28230-190	RAL 7021	Powder Coated	Slim-Line	RoHS	No
28230-191	RAL 7021	Powder Coated	Slim-Line	RoHS	No
28230-194	RAL 7021	Powder Coated	Slim-Line	RoHS	No
28230-195	RAL 7021	Powder Coated	Slim-Line	RoHS	No
28230-198	RAL 7021	Powder Coated	Slim-Line	RoHS	No
28230-199	RAL 7021	Powder Coated	Slim-Line	RoHS	No
28230-202	RAL 7021	Powder Coated	Slim-Line	RoHS	No
28230-203	RAL 7021	Powder Coated	Slim-Line	RoHS	No
28230-206	RAL 7021	Powder Coated	Slim-Line	RoHS	No
28230-207	RAL 7021	Powder Coated	Slim-Line	RoHS	No

Catalog Number	Color Code	Finish	Type	Certifications	Quick Ship
28230-210	RAL 7021	Powder Coated	Slim-Line	RoHS	No
28230-211	RAL 7021	Powder Coated	Slim-Line	RoHS	No
28230-214	RAL 7021	Powder Coated	Slim-Line	RoHS	No
28230-215	RAL 7021	Powder Coated	Slim-Line	RoHS	No
28230-024	RAL 7021	Powder Coated	Slim-Line		No
28230-083	RAL 7021	Powder Coated	Slim-Line		No
28230-143	RAL 7021	Powder Coated	Slim-Line		No
28230-218	RAL 7021	Powder Coated	Slim-Line		No
28230-226	RAL 7021	Powder Coated	Slim-Line		No

ADDITIONAL PRODUCT DETAILS

Двери, задние и боковые стенки, верхние крыши, цоколи, панели основания, полки, направляющие монтажные профили, поворотные ролики или регулируемые ножки заказываются отдельно.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE