

Передняя панель вставного модуля для статической трапециевидной ручки



Передняя панель допускает установку пластиковой или алюминиевой ручки трапециевидной формы. Передняя панель может быть экранирована текстильным уплотнителем.

CERTIFICATIONS



FEATURES

Передняя панель, неэкранированная

Передняя панель, алюминий, 2,5 мм, лицевая поверхность анодированная, токопроводящая

SPECIFICATIONS

Глубина мм (D):	2.5mm
Material:	Алюминий
Finish:	Anodized; Passivated
Аксессуар Тип:	Передняя панель
Product Type:	Передняя панель
Type:	Front Panel for Handle (PIU)

Table 1/3

Catalog Number	Rack Height	Rack Width	Package Quantity	Handle Type	Mounting	Front Finish
----------------	-------------	------------	------------------	-------------	----------	--------------

30847-602	3U	3HP	1	Трапецевидной ручкой, антистатическ, Aluminum Profile	Screw-on Front	Anodized
30847-603	3U	4HP	1	Трапецевидной ручкой, антистатическ, Aluminum Profile	Screw-on Front	Anodized
30847-604	3U	5HP	1	Трапецевидной ручкой, антистатическ, Aluminum Profile	Screw-on Front	Anodized
30847-605	3U	6HP	1	Трапецевидной ручкой, антистатическ, Aluminum Profile	Screw-on Front	Anodized
30847-625	6U	3HP	1	Трапецевидной ручкой, антистатическ, Aluminum Profile	Screw-on Front	Anodized
30847-606	3U	7HP	1	Трапецевидной ручкой, антистатическ, Aluminum Profile	Screw-on Front	Anodized
30847-607	3U	8HP	1	Трапецевидной ручкой, антистатическ, Aluminum Profile	Screw-on Front	Anodized
30847-626	6U	4HP	1	Трапецевидной ручкой, антистатическ, Aluminum Profile	Screw-on Front	Anodized
30847-608	3U	10HP	1	Трапецевидной ручкой, антистатическ, Aluminum Profile	Screw-on Front	Anodized

30847-627	6U	5HP	1	Трапецевидной ручкой, антистатическ, Aluminum Profile	Screw-on Front	Anodized
30847-629	6U	7HP	1	Трапецевидной ручкой, антистатическ	Screw-on Front	Anodized
30847-609	3U	12HP	1	Трапецевидной ручкой, антистатическ, Aluminum Profile	Screw-on Front	Anodized
30847-628	6U	6HP	1	Трапецевидной ручкой, антистатическ, Aluminum Profile	Screw-on Front	Anodized
30847-630	6U	8HP	1	Трапецевидной ручкой, антистатическ, Aluminum Profile	Screw-on Front	Anodized
30847-631	6U	10HP	1	Трапецевидной ручкой, антистатическ, Aluminum Profile	Screw-on Front	Anodized
30847-632	6U	12HP	1	Трапецевидной ручкой, антистатическ	Screw-on Front	Anodized

Table 2/3

Catalog Number	Rear Finish	Treated Edges	Complies With	EMC Shielding	Высота мм (H)	Ширина мм (W)
30847-602	Conductive	Нет	IEC 60297-3-101	Нет	128.4mm	14.9mm
30847-603	Conductive	Нет	IEC 60297-3-101	Нет	128.4mm	20mm
30847-604	Conductive	Нет	IEC 60297-3-101	Нет	128.4mm	25mm
30847-605	Conductive	Нет	IEC 60297-3-101	Нет	128.4mm	30.1mm
30847-625	Conductive	Нет	IEC 60297-3-101	Нет	261.8mm	14.9mm


CatalogNumber	Rear Finish	Treated Edges	Complies With	EMC Shielding	Высота мм (H)	Ширина мм(W)
30847-606	Conductive	Нет	IEC 60297-3-101	Нет	128.4mm	35.2mm
30847-607	Conductive	Нет	IEC 60297-3-101	Нет	128.4mm	40.3mm
30847-626	Conductive	Нет	IEC 60297-3-101	Нет	261.8mm	20mm
30847-608	Conductive	Нет	IEC 60297-3-101	Нет	128.4mm	50.5mm
30847-627	Conductive	Нет	IEC 60297-3-101	Нет	261.8mm	25mm
30847-629	Conductive	Нет	IEC 60297-3-101	Нет	261.8mm	35.2mm
30847-609	Conductive	Нет	IEC 60297-3-101	Нет	128.4mm	60.6mm
30847-628	Conductive	Нет	IEC 60297-3-101	Нет	261.8mm	30.1mm
30847-630	Conductive	Нет	IEC 60297-3-101	Нет	261.8mm	40.3mm
30847-631	Conductive	Нет	IEC 60297-3-101	Нет	261.8mm	50.5mm
30847-632	Conductive	Нет	IEC 60297-3-101	Нет	261.8mm	60.6mm

Table 3/3

Catalog Number	Quick Ship
30847-602	No
30847-603	No
30847-604	No
30847-605	No
30847-625	No
30847-606	No

Catalog Number	Quick Ship
30847-607	No
30847-626	No
30847-608	No
30847-627	No
30847-629	No
30847-609	No
30847-628	No
30847-630	No
30847-631	No
30847-632	No

DIAGRAMS

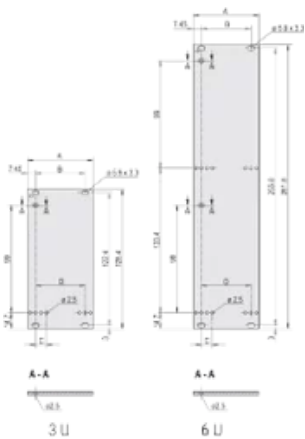

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE