


Комплект вставного модуля с ручкой IEL, с экранированием, черный, 6 U

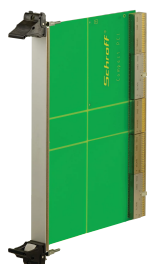

Сменный модуль, с черной ручкой IEL для вставки/извлечения, 6 U, монтаж спереди. U-образная передняя панель обеспечивает экранирование с помощью текстильного уплотнителя.

CERTIFICATIONS



FEATURES

U-образная передняя панель для текстильного уплотнителя

Подходит для нагрузок вставки и извлечения до 700 Н (на пару ручек)

Позволяет выполнить установку микропереключателя

Позволяет выполнить установку кодированных штекеров в соответствии с IEC 60297-3-103/ IEEE 1101.10

SPECIFICATIONS

Material:	Алюминий
Finish:	Anodized; Passivated
Product Type:	Передняя панель
Type:	Front Panel with Handle (PIU)

Table 1/3

Catalog Number	Rack Width	Package Quantity	Handle Type	Mounting	Gasket Type	Front Finish
----------------	------------	------------------	-------------	----------	-------------	--------------

20848-592	4HP	1	IEL	Screw-on Front, Screw-on Rear IO	Textile EMC	Anodized
20848-594	6HP	1	IEL	Screw-on Front, Screw-on Rear IO	Textile EMC	Anodized
20848-596	8HP	1	IEL	Screw-on Front, Screw-on Rear IO	Textile EMC	Anodized
20848-597	10HP	1	IEL	Screw-on Front, Screw-on Rear IO	Textile EMC	Anodized
20848-598	12HP	1	IEL	Screw-on Front, Screw-on Rear IO	Textile EMC	Anodized

Table 2/3

Catalog Number	Rear Finish	Treated Edges	Complies With	EMC Shielding	Высота мм (H)	Rack Height
20848-592	Etched	Нет	IEC 60297-3-102, IEEE 1101.10, IEC 60297-3-103, IEEE 1101.1/11	Да	261.8mm	6U
20848-594	Etched	Нет	IEC 60297-3-102, IEEE 1101.10, IEC 60297-3-103, IEEE 1101.1/11	Да	261.8mm	6U
20848-596	Etched	Нет	IEC 60297-3-102, IEEE 1101.10, IEC 60297-3-103, IEEE 1101.1/11	Да	261.8mm	6U
20848-597	Etched	Нет	IEC 60297-3-102, IEEE 1101.10, IEC 60297-3-103, IEEE 1101.1/11	Да	261.8mm	6U
20848-598	Etched	Нет	IEC 60297-3-102, IEEE 1101.10, IEC 60297-3-103, IEEE 1101.1/11	Да	261.8mm	6U

Table 3/3

Catalog Number	Ширина мм (W)	Quick Ship
----------------	---------------	------------

20848-592	20mm	No
20848-594	30.1mm	No
20848-596	40.3mm	No
20848-597	50.5mm	No
20848-598	60.6mm	No

DIAGRAMS



WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, use, or modification of nVent products may void the warranty and create a safety hazard.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE