

Комплект для вставных модулей с ручкой XL, с экранированием, черный, 6 U



Ручка XL используется для сфер применения, требующих высоких усилий вставки/извлечения, например стандартов VPX или VXS. Подходит для усилий вставки и извлечения до 1500 Н (на пару).

CERTIFICATIONS



FEATURES

Для областей применения, требующих высокого усилия вставки/извлечения, например стандартов VPX или VXS

Доступны дополнительные варианты крепления печатной платы

Для ручки требуется дополнительный литой фиксирующий блок (в сочетании с горизонтальной короткой рейкой/длинной кромкой)

U-образная передняя панель для текстильного уплотнителя

Подходит для усилий вставки/извлечения до 1500 Н (на пару)

IEC 60297-3-102, IEEE 1101.1, IEEE 1101.10

SPECIFICATIONS

Rack Height:	6U
Material:	Алюминий
Finish:	Anodized; Passivated
Product Type:	Передняя панель
Type:	Front Panel with Handle (PIU)
EMC Shielding:	Да


Table 1/2						
Catalog Number	Rack Width	Package Quantity	Handle Type	Mounting	Gasket Type	Front Finish
20848-770	8HP	1	XL	Screw-on Front	Textile EMC	Anodized
20848-771	12HP	1	XL	Screw-on Front	Textile EMC	Anodized
20848-769	4HP	1	XL	Screw-on Front	Textile EMC	Anodized

Table 2/2						
Catalog Number	Rear Finish	Treated Edges	Complies With	Высота мм (H)	Ширина мм (W)	Quick Ship
20848-770	Etched	Нет	IEC 60297-3-102, IEEE 1101.10, IEEE 1101.1	261.8mm	40.3mm	No
20848-771	Etched	Нет	IEC 60297-3-102, IEEE 1101.10, IEEE 1101.1	261.8mm	60.6mm	No
20848-769	Etched	Нет	IEC 60297-3-102, IEEE 1101.10, IEEE 1101.1	261.8mm	20mm	No

ADDITIONAL PRODUCT DETAILS

Комплект с передней панелью для микропереключателя по запросу.

DIAGRAMS

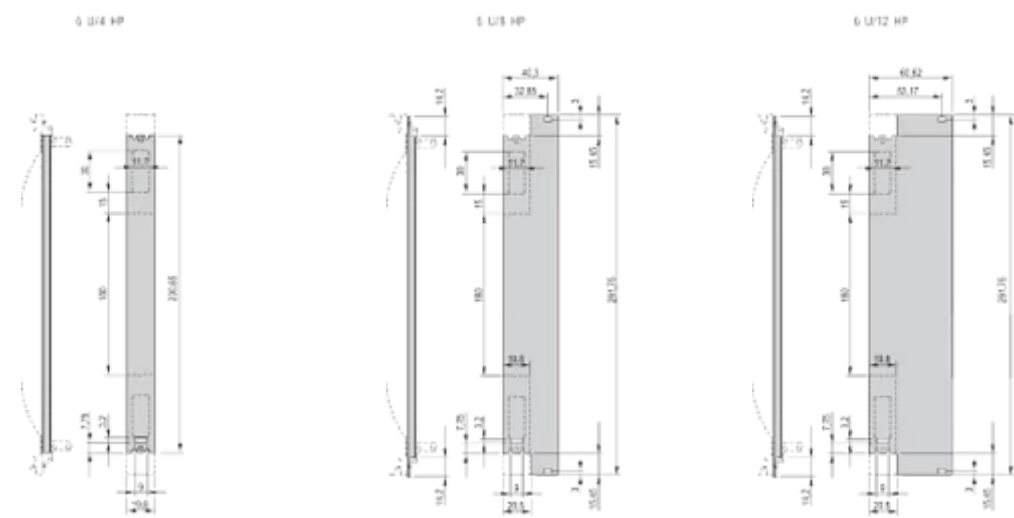

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE