


Передняя панель U-образная для вставного модуля для ручки XL

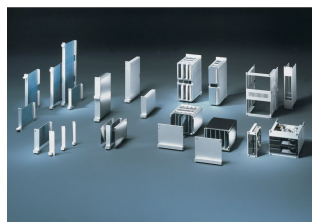

Передняя панель для ручки XL. Возможно экранирование с текстильной прокладкой. С вырезом или без выреза для микровыключателя.

CERTIFICATIONS



FEATURES

алюминий, лицевая поверхность анодированная, sides and rear conductive

Подходит для втулки и винта с проточкой

U-образный передний профиль, с возможностью экранирования, для ручки устройства вставки/извлечения, тип XL

SPECIFICATIONS

Material:	Алюминий
Finish:	Anodized; Passivated
Аксессуар Тип:	Передняя панель
Product Type:	Передняя панель
Type:	Front Panel for Handle (PIU)
EMC Shielding:	No (Retrofittable)

Table 1/3

Catalog Number	Rack Width	Package Quantity	Handle Type	Mounting	Gasket Type	Front Finish
----------------	------------	------------------	-------------	----------	-------------	--------------

30849-153	4HP	1	XL	Screw-on Front	Textile EMC	Anodized
30849-154	4HP	1	XL	Screw-on Front	Textile EMC	Anodized
30849-156	8HP	1	XL	Screw-on Front	Textile EMC	Anodized
30849-155	8HP	1	XL	Screw-on Front	Textile EMC	Anodized
30849-158	12HP	1	XL	Screw-on Front	Textile EMC	Anodized
30849-157	12HP	1	XL	Screw-on Front	Textile EMC	Anodized

Table 2/3

Catalog Number	Rear Finish	Treated Edges	Complies With	Глубина мм (D)	Высота мм (H)	Rack Height
30849-153	Conductive	Нет	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	261.8mm	6U
30849-154	Conductive	Нет	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	261.8mm	6U
30849-156	Conductive	Нет	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	261.8mm	6U
30849-155	Conductive	Нет	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	261.8mm	6U
30849-158	Conductive	Нет	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	261.8mm	6U
30849-157	Conductive	Нет	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	261.8mm	6U

Table 3/3

Catalog Number	Ширина мм (W)	Quick Ship
30849-153	20mm	No
30849-154	20mm	No


Catalog Number	Ширина мм (W)	Quick Ship
30849-156	40.3mm	No
30849-155	40.3mm	No
30849-158	60.6mm	No
30849-157	60.6mm	No

ADDITIONAL PRODUCT DETAILS

Поставка исключительно в размере упаковочной единицы. Текстильный уплотнитель ЭМС и микровыключатель заказываются отдельно.

Обратите внимание, что поставки доступны в указанных стандартных товарных партиях (товарная партия, например, 5 шт., 10 шт., 50 шт. и т. д.). Другие объемы заказов (например, 2 шт.) могут округляться вверх до следующего возможного размера стандартной товарной партии.

DIAGRAMS

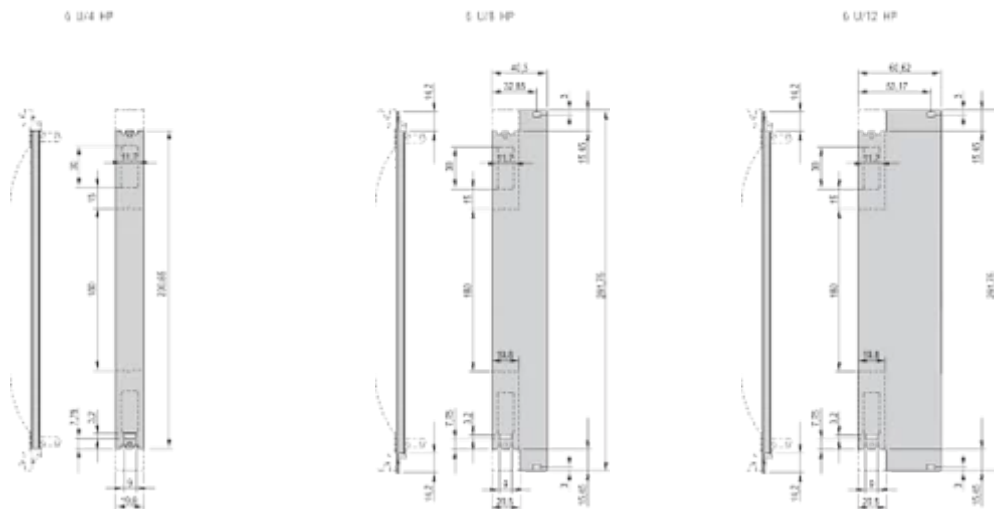

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE