

Передняя панель для сменного модуля для ручки формы 1



Плоская передняя панель. Позволяет установку трапецевидной ручки формы 1 для извлечения. Передняя панель может быть экранирована текстильным уплотнителем.

CERTIFICATIONS



FEATURES

Передняя панель, неэкранированная

Передняя панель, алюминий, 2,5 мм, лицевая поверхность анодированная, тыльная поверхность электропроводящая

SPECIFICATIONS

Material:	Алюминий
Finish:	Anodized; Passivated
Аксессуар Тип:	Передняя панель
Product Type:	Передняя панель
Type:	Front Panel with Handle (PIU)

Table 1/3

Catalog Number	Rack Height	Rack Width	Package Quantity	Handle Type	Mounting	Front Finish
----------------	-------------	------------	------------------	-------------	----------	--------------

30847-661	3U	6HP	1	Трапецевидная форма, тип 1	Screw-on Front	Anodized
30847-659	3U	4HP	1	Трапецевидная форма, тип 1	Screw-on Front	Anodized
30847-660	3U	5HP	1	Трапецевидная форма, тип 1	Screw-on Front	Anodized
30847-662	3U	7HP	1	Трапецевидная форма, тип 1	Screw-on Front	Anodized
30847-663	3U	8HP	1	Трапецевидная форма, тип 1	Screw-on Front	Anodized
30847-666	6U	4HP	1	Трапецевидная форма, тип 1	Screw-on Front	Anodized
30847-664	3U	10HP	1	Трапецевидная форма, тип 1	Screw-on Front	Anodized
30847-667	6U	5HP	1	Трапецевидная форма, тип 1	Screw-on Front	Anodized
30847-665	3U	12HP	1	Трапецевидная форма, тип 1	Screw-on Front	Anodized
30847-668	6U	6HP	1	Трапецевидная форма, тип 1	Screw-on Front	Anodized
30847-669	6U	7HP	1	Трапецевидная форма, тип 1	Screw-on Front	Anodized
30847-670	6U	8HP	1	Трапецевидная форма, тип 1	Screw-on Front	Anodized
30847-671	6U	10HP	1	Трапецевидная форма, тип 1	Screw-on Front	Anodized
30847-672	6U	12HP	1	Трапецевидная форма, тип 1	Screw-on Front	Anodized

Table 2/3

Catalog Number	Rear Finish	Treated Edges	Complies With	Глубина мм (D)	EMC Shielding	Высота мм (H)
----------------	-------------	---------------	---------------	----------------	---------------	---------------

30847-661	Conductive	Нет	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	Нет	128.4mm
30847-659	Conductive	Нет	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	Нет	128.4mm
30847-660	Conductive	Нет	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	Нет	128.4mm
30847-662	Conductive	Нет	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	Нет	128.4mm
30847-663	Conductive	Нет	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	Нет	128.4mm
30847-666	Conductive	Нет	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	Нет	261.8mm
30847-664	Conductive	Нет	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	Нет	128.4mm
30847-667	Conductive	Нет	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	Нет	261.8mm
30847-665	Conductive	Нет	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	Нет	128.4mm
30847-668	Conductive	Нет	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	Нет	261.8mm
30847-669	Conductive	Нет	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	Нет	261.8mm
30847-670	Conductive	Нет	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	Нет	261.8mm
30847-671	Conductive	Нет	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	Нет	261.8mm
30847-672	Conductive	Нет	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	Нет	261.8mm


Table 3/3

Catalog Number	Ширина мм (W)	Quick Ship
----------------	---------------	------------

30847-661	30.1mm	No
30847-659	20mm	No
30847-660	25mm	No
30847-662	35.2mm	No
30847-663	40.3mm	No
30847-666	20mm	No
30847-664	50.5mm	No
30847-667	25mm	No
30847-665	60.6mm	No
30847-668	30.1mm	No
30847-669	35.2mm	No
30847-670	40.3mm	No
30847-671	50.5mm	No
30847-672	60.6mm	No

ADDITIONAL PRODUCT DETAILS

Обратите внимание, что поставки доступны в указанных стандартных товарных партиях (товарная партия, например, 5 шт., 10 шт., 50 шт. и т. д.). Другие объемы заказов (например, 2 шт.) могут округляться вверх до следующего возможного размера стандартной товарной партии.

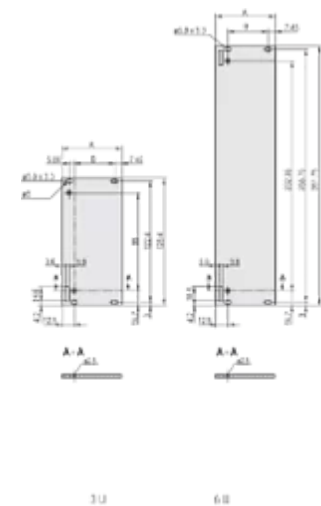

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE