


Передняя панель ProPasPRO, полная ширина, Без экранирования

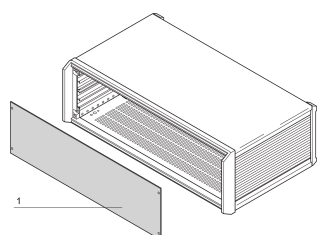

Передняя панель по всей ширине корпуса ProPasPRO крепится к раме корпуса.

CERTIFICATIONS



FEATURES

Алюминиевая панель, 2,0 мм (84 HP 2. 5 мм)

SPECIFICATIONS

Material:	Алюминий
Finish:	Anodized
Аксессуар Тип:	Передняя панель
Product Type:	Передняя панель

Table 1/2

Catalog Number	Rack Height	Rack Width	Package Quantity	Front Finish	Rear Finish	Treated Edges
20850-128	2U	42HP	1	Anodized	Anodized	Нет
20850-134	3U	28HP	1	Anodized	Anodized	Нет
20850-129	2U	63HP	1	Anodized	Anodized	Нет

CatalogNumber	Rack Height	Rack Width	Package Quantity	Front Finish	Rear Finish	Treated Edges
20850-135	3U	42HP	1	Anodized	Anodized	Нет
20850-142	4U	42HP	1	Anodized	Anodized	Нет
20850-136	3U	63HP	1	Anodized	Anodized	Нет
20850-130	2U	84HP	1	Anodized	Anodized	Нет
20850-143	4U	63HP	1	Anodized	Anodized	Нет
20850-137	3U	84HP	1	Anodized	Anodized	Нет
20850-144	4U	84HP	1	Anodized	Anodized	Нет
20850-158	6U	84HP	1	Anodized	Conductive	Нет

Table 2/2				
Catalog Number	Глубина мм	Высота мм	Ширина мм	Quick Ship
20850-128	2mm	84mm	238.7mm	No
20850-134	2mm	128.5mm	167.6mm	No
20850-129	2mm	84mm	345.4mm	No
20850-135	2mm	128.5mm	238.7mm	No
20850-142	2mm	172.9mm	238.7mm	No
20850-136	2mm	128.5mm	345.4mm	No
20850-130	2.5mm	84mm	452mm	No
20850-143	2mm	172.9mm	345.4mm	No
20850-137	2.5mm	128.5mm	452mm	No

Catalog Number	Глубина мм	Высота мм	Ширина мм	Quick Ship
20850-144	2.5mm	172.9mm	452mm	No
20850-158	2.5mm	261.8mm	452mm	No

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE