


Тестовая розетка для одиночного светодиода, Ø 2 мм

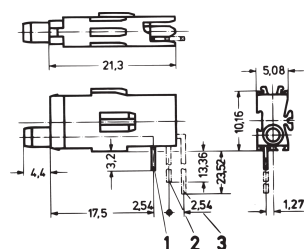

Тестовые гнезда для монтажной поверхности 1 и 2, короткие и длинные.

CERTIFICATIONS



FEATURES

Длинный тип для монтажной поверхности 1 и 2

Укороченная конструктивная форма для монтажной плоскости 1

SPECIFICATIONS

Works With: Передние панели

Product Type: Светодиод

Type: Single LED

Table 1/1

Catalog Number	Package Quantity	Socket Type	Quick Ship
69004-086	1	Long	No
69004-130	1	Short	No
69004-087			No

ADDITIONAL PRODUCT DETAILS

Dimensions of connecting pins: 0,3 × 0,6 mm.

Обратите внимание, что поставки доступны в указанных стандартных товарных партиях (товарная партия, например, 5 шт., 10 шт., 50 шт. и т. д.). Другие объемы заказов (например, 2 шт.) могут округляться вверх до следующего возможного размера стандартной товарной партии.

Required front panel drill hole: Ø 4 mm.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE