


Проводящая полоса для пайки

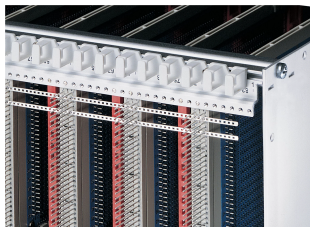

Рациональное соединение выводов с одинаковым шагом и равным потенциалом. Может использоваться для разъемов по EN 60603-2 (DIN 41612)) с контактными штырями под накрутку.

CERTIFICATIONS



FEATURES

Рациональное соединение выводов с одинаковым шагом и равным потенциалом

Подходит для разъемов в соответствии с EN 60603 (DIN 41612) с контактом под монтаж проволочной накруткой

SPECIFICATIONS

Product Type:	Busbar
Material:	Copper
Works With:	Передние панели
Finish:	Tin Plated

Table 1/1

Catalog Number	Package Quantity	Connection Type	Quick Ship
60800-064	1	Pins, 0.6 x 0.6 mm	No
60800-080	1	Pins, 1.0 x 1.0 mm	No

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE