


Test Adaptor for VMEbus

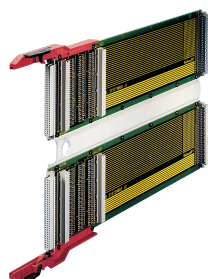

Тестовый адаптер для плат VMEbus для доступа к контрольным точкам на печатной плате.

CERTIFICATIONS



FEATURES

Маршрутизация и укладка слоев соответствуют требованиям шины VME

Для измерения тока и напряжения (V/I), (a)

Дополнительные измерительные контакты, например, для измерительных наконечников осциллоскопа (b)

1 слот для второго испытываемого прибора, 1 слот для платы согласования

Тестовые адаптеры 6 U состоят из двух тестовых адаптеров 3 U, соединенных промежуточным адаптером

Линии подачи напряжения рассчитаны на 2 A

SPECIFICATIONS

Table 1/2

Catalog Number	Type	Connector Type	Board Depth	Rack Height	Measuring Field	Number of Layers
23022-002	VMEbus	C96, System Bus, C96, I/O Bus	160mm	6U	Current, Voltage	6
23021-002	VMEbus	C96, System Bus	220mm	3U	Current, Voltage	6

CatalogNumber	Type	ConnectorType	Board Depth	Rack Height	MeasuringField	Number of Layers
23021-100	VMEbus	C96, I/O Bus	160mm	3U	Current, Voltage	6
23021-001	VMEbus	C96, System Bus	160mm	3U	Current, Voltage	6
23021-101	VMEbus	C96, I/O Bus	220mm	3U	Current, Voltage	6
23022-010	VMEbus	C96, System Bus, C96, I/O Bus	280mm	6U	Current, Voltage	6
23022-004	VMEbus	C96, System Bus, C96, I/O Bus	220mm	6U	Current, Voltage	6

Table 2/2

Catalog Number	Package Quantity	Quick Ship
23022-002	1	No
23021-002	1	No
23021-100	1	No
23021-001	1	No
23021-101	1	No
23022-010	1	No
23022-004	1	No

ADDITIONAL PRODUCT DETAILS

Информация по испытательному адаптеру 9 U VMEbus приводится в описании кронштейна промежуточного адаптера, 9 U, 220 мм, 350 мм.

P1 = шина системы, P2 = шина ввода/вывода.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper

installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE