


U-образная Передняя Панель, С возможностью экранирования, Вырезы D-Sub

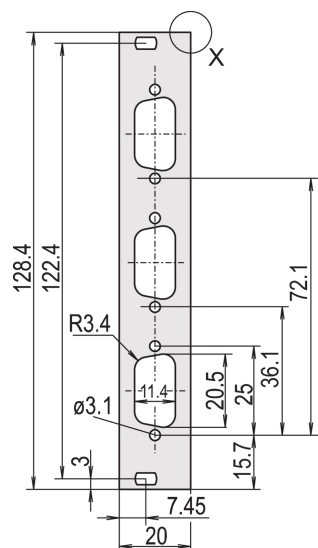

U-образная передняя панель с вырезом для разъемов D-Sub. Возможность экранирования тканевой ЭМС-прокладкой.

CERTIFICATIONS



FEATURES

U-образный профиль, передняя панель, алюминий, 2,5 мм, лицевая поверхность анодированная, тыльная поверхность электропроводящая

Для текстильного уплотнителя ЭМС

SPECIFICATIONS

Глубина мм (D):	2.5mm
Rack Height:	3U
Rack Width:	4HP
Material:	Алюминий

Finish: Anodized; Passivated

Аксессуар Тип: Передняя панель

Product Type: Передняя панель

Type: Front Panel without Handle

EMC Shielding: No (Retrofittable)

Table 1/2

Catalog Number	Package Quantity	Mounting	EMC Gasket Type	Front Finish	Rear Finish	Number of Pins
30849-749	1	Screw-on Front	Textile	Anodized	Conductive	(1) 9
30849-750	1	Screw-on Front	Textile	Anodized	Conductive	(2) 9
30849-751	1	Screw-on Front	Textile	Anodized	Conductive	(3) 9
30849-752	1	Screw-on Front	Textile	Anodized	Conductive	(1) 15
30849-753	1	Screw-on Front	Textile	Anodized	Conductive	(2) 15
30849-754	1	Screw-on Front	Textile	Anodized	Conductive	(1) 25
30849-755	1	Screw-on Front	Textile	Anodized	Conductive	(2) 25

Table 2/2

Catalog Number	Treated Edges	Complies With	Высота мм (H)	Ширина мм (W)	Quick Ship
30849-749	Нет	IEC 60297-3-101, IEEE 1101.1/10	128.4mm	20mm	No
30849-750	Нет	IEC 60297-3-101, IEEE 1101.1/10	128.4mm	20mm	No
30849-751	Нет	IEC 60297-3-101, IEEE 1101.1/10	128.4mm	20mm	No
30849-752	Нет	IEC 60297-3-101, IEEE 1101.1/10	128.4mm	20mm	No
30849-753	Нет	IEC 60297-3-101, IEEE 1101.1/10	128.4mm	20mm	No
30849-754	Нет	IEC 60297-3-101, IEEE 1101.1/10	128.4mm	20mm	No
30849-755	Нет	IEC 60297-3-101, IEEE 1101.1/10	128.4mm	20mm	No

ADDITIONAL PRODUCT DETAILS

Крепежный материал (втулки, винты с проточкой) заказывается отдельно.

Поставка исключительно в размере товарной партии. Цена указана за отдельную единицу.

Текстильная ЭМС-прокладка заказывается отдельно.

Обратите внимание, что поставки доступны в указанных стандартных товарных партиях (товарная партия, например, 5 шт., 10 шт., 50 шт. и т. д.). Другие объемы заказов (например, 2 шт.) могут округляться вверх до следующего возможного размера стандартной товарной партии.

DIAGRAMS





WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE