


Декоративная панель для 19-дюймовой поворотной рамы Varistar

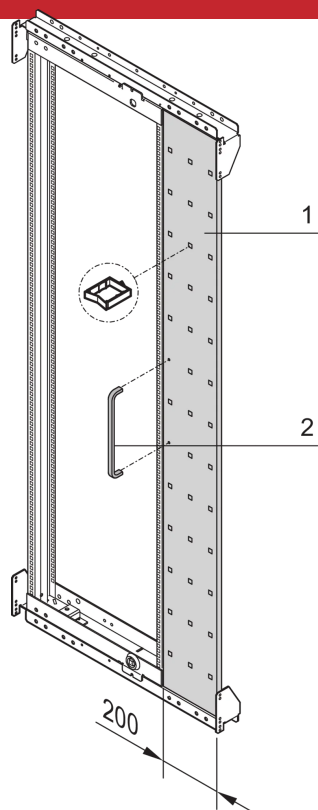

Поворотная рама Varistar позволяет оптимально использовать пространство внутри шкафа. Поворотные рамы поставляются вместе с ручками.

CERTIFICATIONS



FEATURES

В комплект входит ручка и вырез для кабельных наконечников

Для закрытия зазора между поворотной рамой и каркасом для шкафов шириной 800 мм

Макс. угол поворота: 120 или 160

Для поворотной рамы с допустимой нагрузкой 150 кг, для обеспечения безопасности рекомендуется установка ограничителя хода

Замок № 333

SPECIFICATIONS

Table 1/2

Catalog Number	Type	Material	Frame Material	Color	Color Code	Rack Height
21130-435	Swing	Сталь	Сталь	Black Grey	RAL 7021	38U
21130-437	Swing	Сталь	Сталь	Black Grey	RAL 7021	47U
21130-433	Swing	Сталь	Сталь	Black Grey	RAL 7021	29U
21130-447	Swing	Сталь	Сталь	Black Grey	RAL 7021	47U
21130-443	Swing	Сталь	Сталь	Black Grey	RAL 7021	29U
21130-445	Swing	Сталь	Сталь	Black Grey	RAL 7021	38U

Table 2/2

Catalog Number	Ширина мм	Works With	Finish	Package Quantity	Quick Ship
21130-435	800mm	Varistar CP	Powder Coated	1	No
21130-437	800mm	Varistar CP	Powder Coated	1	No
21130-433	800mm	Varistar CP	Powder Coated	1	No
21130-447	800mm	Varistar CP	Powder Coated	2	No
21130-443	800mm	Varistar CP	Powder Coated	2	No
21130-445	800mm	Varistar CP	Powder Coated	2	No

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE