


19-дюймовая панель / монтажный профиль Varistar CP

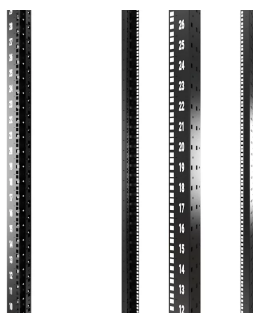

Крепление для направляющей с регулируемым шагом. В шкафах шириной 600 мм возможна сборка прямо на раму. При ширине 800 мм необходим кронштейн адаптера для уменьшенной ширины, для установки неполной высоты необходимы заглубляющие распорки.

FEATURES

19-дюймовый монтажный профиль с U-шкалой высоты

Установка по глубине определяется шагом 25 мм

В соответствии с IEC 60297-1 (DIN 41 494, часть 1)

SPECIFICATIONS

Finish: Powder Coated

Product Type: Slide Mount

Material: Сталь

Table 1/1

Catalog Number	Rack Height	Высота мм	Package Quantity	Color	Color Code	Quick Ship
24630-013	42U	2000mm	4	Jet Black	RAL 9005	No
24630-015	52U	2450mm	4	Jet Black	RAL 9005	No
24630-014	47U	2200mm	4	Jet Black	RAL 9005	No

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE