


Varistar CP Seismic Base Plate, IP55, One-Piece

The base plate is solid and covers the base of the cabinet.

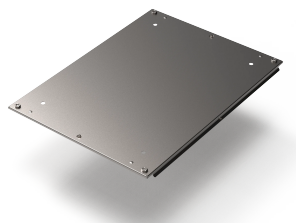

FEATURES

The base plate is solid and covers the base of the cabinet

Is assembled from outside

SPECIFICATIONS

Product Type: Cabinet/Rack Base

Protection Rating: IP55

Material: Сталь

Table 1/2

Catalog Number	Ширина мм	Глубина мм	Package Quantity	Color	Color Code	Complies With
20630-301	600mm	600mm	1	Black Grey	RAL 7021	IEC 61587-1, IEC 61587-2, IEC 60529
20630-302	600mm	800mm	1	Black Grey	RAL 7021	IEC 61587-1, IEC 61587-2, IEC 60529
20630-303	1000mm	1000mm	1	Black Grey	RAL 7021	IEC 61587-1, IEC 61587-2, IEC 60529
20630-304	600mm	1200mm	1	Black Grey	RAL 7021	IEC 61587-1, IEC 61587-2, IEC 60529

CatalogNumber	Ширина мм	Глубина мм	Package Quantity	Color	Color Code	Complies With
20630-305	800mm	600mm	1	Black Grey	RAL 7021	IEC 61587-1, IEC 61587-2, IEC 60529
20630-306	800mm	800mm	1	Black Grey	RAL 7021	IEC 61587-1, IEC 61587-2, IEC 60529
20630-307	800mm	1000mm	1	Black Grey	RAL 7021	IEC 61587-1, IEC 61587-2, IEC 60529
20630-308	1200mm	1200mm	1	Black Grey	RAL 7021	IEC 61587-1, IEC 61587-2, IEC 60529

Table 2/2

Catalog Number	Finish	Type	Works With	Quick Ship
20630-301	Powder Coated	Base Plate, Plain	Varistar CP	No
20630-302	Powder Coated	Base Plate, Plain	Varistar CP	No
20630-303	Powder Coated	Base Plate, Plain	Varistar CP	No
20630-304	Powder Coated	Base Plate, Plain	Varistar CP	No
20630-305	Powder Coated	Base Plate, Plain	Varistar CP	No
20630-306	Powder Coated	Base Plate, Plain	Varistar CP	No
20630-307	Powder Coated	Base Plate, Plain	Varistar CP	No
20630-308	Powder Coated	Base Plate, Plain	Varistar CP	No

ADDITIONAL PRODUCT DETAILS

This base plate is used for applications which don't require cable entry from the base.

Please purchase the grounding kit separately.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE