


Varistar CP Seismic Base Plate, Multi-Piece

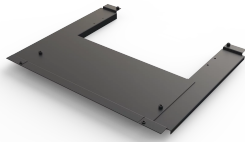

Multi piece base plate is assembled from inside.

Please order grounding, cover plate, brush strip or filter mat separately.

FEATURES

To cover the base opening

The multi-piece base plate is open at the rear (opening to rear 200 mm deep, no rear opening with 300 mm cabinet depth)

SPECIFICATIONS

Product Type: Cabinet/Rack Base

Material: Сталь

Table 1/2

Catalog Number	Ширина мм	Глубина мм	Package Quantity	Color	Color Code	Complies With
20630-293	600mm	600mm	1	Black Grey	RAL 7021	IEC 61587-1, IEC 61587-2
20630-294	600mm	800mm	1	Black Grey	RAL 7021	IEC 61587-1, IEC 61587-2
20630-295	600mm	1000mm	1	Black Grey	RAL 7021	IEC 61587-1, IEC 61587-2
20630-296	600mm	1200mm	1	Black Grey	RAL 7021	IEC 61587-1, IEC 61587-2
20630-297	800mm	600mm	1	Black Grey	RAL 7021	IEC 61587-1, IEC 61587-2
20630-298	800mm	800mm	1	Black Grey	RAL 7021	IEC 61587-1, IEC 61587-2

CatalogNumber	Ширина мм	Глубина мм	Package Quantity	Color	Color Code	Complies With
20630-299	800mm	1000mm	1	Black Grey	RAL 7021	IEC 61587-1, IEC 61587-2
20630-300	800mm	1200mm	1	Black Grey	RAL 7021	IEC 61587-1, IEC 61587-2

Table 2/2

Catalog Number	Finish	Type	Works With	Quick Ship
20630-293	Powder Coated	Base Plate, Plain	Varistar CP	No
20630-294	Powder Coated	Base Plate, Plain	Varistar CP	No
20630-295	Powder Coated	Base Plate, Plain	Varistar CP	No
20630-296	Powder Coated	Base Plate, Plain	Varistar CP	No
20630-297	Powder Coated	Base Plate, Plain	Varistar CP	No
20630-298	Powder Coated	Base Plate, Plain	Varistar CP	No
20630-299	Powder Coated	Base Plate, Plain	Varistar CP	No
20630-300	Powder Coated	Base Plate, Plain	Varistar CP	No

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE