


# C-Channel U-Shaped Washer

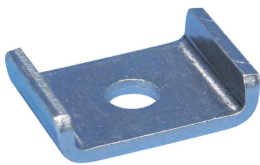

## FEATURES

U-shaped wrap around washer

For use with C-Profiles

## SPECIFICATIONS

**Finish:** Electrogalvanized

**Material:** Сталь

Table 1/2


Catalog Number	Article Number	A	B	C	Thickness (T)	Hole Size (HS)
PLNE1208	588260	31 mm	30 mm	13.5 mm	2 mm	8.5 mm
PLNE010	588250	28 mm	30 mm	15 mm	2 mm	10.5 mm
PLUNI10	588290	35 mm	30 mm	10 mm	3 mm	10.5 mm
PLNE3408	588280	39 mm	30 mm	17.5 mm	3 mm	8.5 mm

Table 2/2

Catalog Number	Article Number	Channel Type
PLNE1208	588260	E0L, E0, E1

Catalog Number	Article Number	Channel Type
PLNE010	588250	E0, E0L
PLUN110	588290	E1, E2, E2L
PLNE3408	588280	E2, E3, E4

### DIAGRAMS

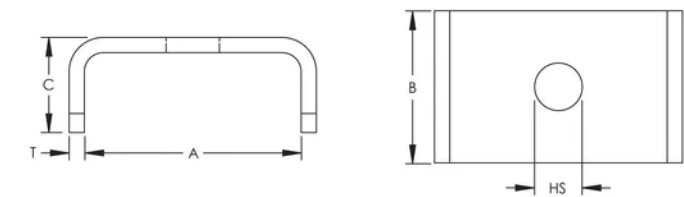

### WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

#### North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

#### Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

#### Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

#### APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE

