

nVent CADDY Macrofix Plus Kombi with Combination Nut



FEATURES

Includes easy closing mechanism

Age-resistant lining

Category II noise reduction according to DIN EN ISO 3822-1

Compliant for sound insulation design according to DIN 4109

Reaction-to-fire classification is "E" in compliance with DIN EN 13501-1

SPECIFICATIONS

Rod Size (RS): M8;M10;1/2"

Color: Черный

Finish: Electrogalvanized

Temperature: -50 to 110 °C

Table 1/2

Catalog Number	Article Number	Material	Outer Diameter (OD)	NB/DN	Width (W)	Thickness (T)
MPK031	586754	Сталь, EPDM-SBR Rubber	25 - 31 mm	20	20 mm	1 mm
MPK037	586755	Сталь, EPDM-SBR Rubber	31 - 37 mm	25	20 mm	1 mm
MPK044	586756	Сталь, EPDM-SBR Rubber	37 - 44 mm	32	20 mm	1 mm

CatalogNumber	Article Number	Material	Outer Diameter (OD)	NB/DN	Width (W)	Thickness (T)
MPK051	586757	Сталь, EPDM-SBR Rubber	45 - 51 mm	40	21 mm	1.25 mm
MPK058	586758	Сталь, EPDM-SBR Rubber	50 - 58 mm		21 mm	1.25 mm
MPK068	586759	Сталь, EPDM-SBR Rubber	58 - 68 mm	50	21 mm	1.25 mm
MPK078	586760	Сталь, EPDM-SBR Rubber	68 - 78 mm	65	23 mm	1.5 mm
MPK088	586761	Сталь, EPDM-SBR Rubber	78 - 88 mm		23 mm	1.5 mm
MPK098	586762	Сталь, EPDM-SBR Rubber	88 - 98 mm	80	23 mm	1.75 mm
MPK118	586763	Сталь, EPDM-SBR Rubber	108 - 118 mm	100	23 mm	1.75 mm
MPK138	586764	Сталь, EPDM-SBR Rubber	128 - 138 mm		23 mm	2 mm
MPK148	586765	Сталь, EPDM-SBR Rubber	138 - 148 mm	125	25 mm	2 mm
MPK160	586766	Сталь, EPDM-SBR Rubber	150 - 160 mm		25 mm	2 mm
MPK170	586767	Сталь, EPDM-SBR Rubber	160 - 170 mm	150	25 mm	2 mm
MPK201	586768	Сталь, EPDM-SBR Rubber	190 - 200 mm		27 mm	2.25 mm

Table 2/2


Catalog Number	Article Number	Screw Diameter (Sc)	Screw Length (L)	Static Load	Unit Weight
MPK031	586754	6 mm	32mm	1000N	0.11 kg
MPK037	586755	6 mm	32mm	1000N	0.12 kg
MPK044	586756	6 mm	37mm	1000N	0.12 kg
MPK051	586757	6 mm	37mm	1500N	0.14 kg

Catalog Number	Article Number	Screw Diameter (Sc)	Screw Length (L)	Static Load	Unit Weight
MPK058	586758	6 mm	37mm	1500N	0.15 kg
MPK068	586759	6 mm	40mm	1500N	0.16 kg
MPK078	586760	6 mm	40mm	2000N	0.19 kg
MPK088	586761	6 mm	40mm	2000N	0.2 kg
MPK098	586762	6 mm	45mm	2500N	0.27 kg
MPK118	586763	6 mm	50mm	2500N	0.3 kg
MPK138	586764	6 mm	50mm	3000N	0.34 kg
MPK148	586765	6 mm	50mm	3200N	0.4 kg
MPK160	586766	6 mm	50mm	3200N	0.42 kg
MPK170	586767	6 mm	50mm	3200N	0.42 kg
MPK201	586768	6 mm	50mm	3600N	0.63 kg

ADDITIONAL PRODUCT DETAILS

Lining is EPDM rubber.

DIAGRAMS

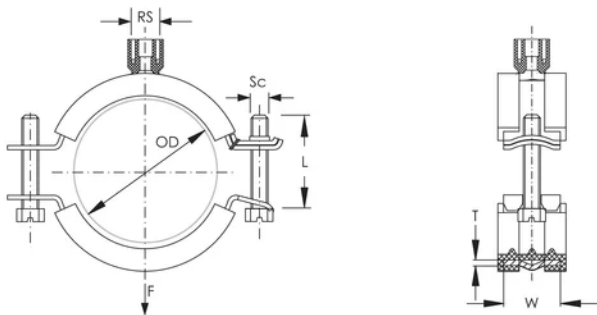

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

