

nVent CADDY Speed Link SLK with Angle Bracket



CERTIFICATIONS



FEATURES

Complete system includes wire, locking device and pre-assembled angle bracket end fitting

Ideal for attaching to concrete, steel or wood surfaces

Simple alternative to jack chain and additional hardware

SPECIFICATIONS

Static Load Safety Factor: 5:1
Finish: Electrogalvanized
Complies With: SMACNA HVAC-DCS

Table 1/3

Catalog Number	Article Number	Material	Wire Rope Diameter	Wire Rope Length	A	Hole Size (HS)
SLK15L1AB	196500	Steel, Zinc Alloy, Polypropylene	1.5 mm	1m	22.6 mm	7.1 mm

CatalogNumber	Article Number	Material	Wire Rope Diameter	Wire Rope Length	A	Hole Size (HS)
SLK15L2AB	196501	Steel, Zinc Alloy, Polypropylene	1.5 mm	2m	22.6 mm	7.1 mm
SLK15L3AB	196502	Steel, Zinc Alloy, Polypropylene	1.5 mm	3m	22.6 mm	7.1 mm
SLK15L5AB	196503	Steel, Zinc Alloy, Polypropylene	1.5 mm	5m	22.6 mm	7.1 mm
SLK2L2AB	196529	Steel, Zinc Alloy, Polypropylene	2 mm	2m	22.6 mm	7.1 mm
SLK2L3AB	196530	Steel, Zinc Alloy, Polypropylene	2 mm	3m	22.6 mm	7.1 mm
SLK2L5AB	196531	Steel, Zinc Alloy, Polypropylene	2 mm	5m	22.6 mm	7.1 mm
SLK3L10AB	196716	Steel, Zinc Alloy, Polypropylene	3 mm	10m	22.6 mm	7.1 mm
SLK3L2AB	196713	Steel, Zinc Alloy, Polypropylene	3 mm	2m	22.6 mm	7.1 mm
SLK3L5AB	196715	Steel, Zinc Alloy, Polypropylene	3 mm	5m	22.6 mm	7.1 mm

Table 2/3


Catalog Number	Article Number	Height (H)	Width (W)	Thickness (T)	Angle (a)	Static Load
SLK15L1AB	196500	55 mm	19 mm	12.5 mm	90 ° Max	195N
SLK15L2AB	196501	55 mm	19 mm	12.5 mm	90 ° Max	195N
SLK15L3AB	196502	55 mm	19 mm	12.5 mm	90 ° Max	195N
SLK15L5AB	196503	55 mm	19 mm	12.5 mm	90 ° Max	195N
SLK2L2AB	196529	55 mm	19 mm	12.5 mm	90 ° Max	440N

CatalogNumber	Article Number	Height (H)	Width (W)	Thickness (T)	Angle (a)	Static Load
SLK2L3AB	196530	55 mm	19 mm	12.5 mm	90 ° Max	440N
SLK2L5AB	196531	55 mm	19 mm	12.5 mm	90 ° Max	440N
SLK3L10AB	196716	62 mm	24 mm	16 mm	90 ° Max	890N
SLK3L2AB	196713	62 mm	24 mm	16 mm	90 ° Max	890N
SLK3L5AB	196715	62 mm	24 mm	16 mm	90 ° Max	890N

Table 3/3

Catalog Number	Article Number	Certifications
SLK15L1AB	196500	ITB, UL, cUL
SLK15L2AB	196501	ITB, UL, cUL
SLK15L3AB	196502	cUL, ITB, UL
SLK15L5AB	196503	ITB, UL, cUL
SLK2L2AB	196529	ITB, UL, cUL
SLK2L3AB	196530	ITB, UL, cUL
SLK2L5AB	196531	ITB, UL, cUL
SLK3L10AB	196716	
SLK3L2AB	196713	
SLK3L5AB	196715	

DIAGRAMS

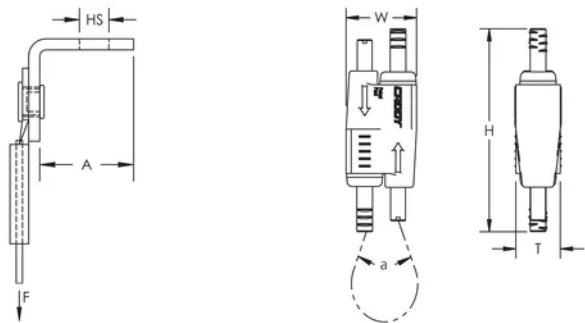

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

