

nVent CADDY Superfix 243 M8



CERTIFICATIONS



FEATURES

Includes easy closing mechanism

Combo head bolt works with slotted, hex, or Phillips drivers

Category II noise reduction according to DIN EN ISO 3822-1

Compliant for sound insulation design according to DIN 4109

Reaction-to-fire classification is "E" in compliance with DIN EN 13501-1

SPECIFICATIONS

Color: Черный
Finish: Electrogalvanized
Temperature: -50 to 110 °C

Table 1/2

Catalog Number	Article Number	Material	Outer Diameter (OD)	NB/DN	Rod Size (RS)	Width (W)
SXE019	400056	Сталь, EPDM-SBR Rubber	15 - 19 mm	10	M8	20 mm

CatalogNumber	Article Number	Material	Outer Diameter (OD)	NB/DN	Rod Size (RS)	Width (W)
SXE023	400057	Сталь, EPDM-SBR Rubber	20 - 23 mm	15	M8	20 mm
SXE028	400058	Сталь, EPDM-SBR Rubber	26 - 30 mm	20	M8	20 mm
SXE035	400059	Сталь, EPDM-SBR Rubber	31 - 36 mm	25	M8	20 mm
SXE043	400060	Сталь, EPDM-SBR Rubber	40 - 43 mm	32	M8	20 mm
SXE052	400062	Сталь, EPDM-SBR Rubber	48 - 53 mm	40	M8	20 mm
SXE058	589310	Сталь, EPDM-SBR Rubber	50 - 55 mm		M8	20 mm
SXE061	589320	Сталь, EPDM-SBR Rubber	60 - 64 mm	50	M8	20 mm
SXE014	400055	Сталь, EPDM-SBR Rubber	12 - 16 mm	8	M8	20 mm

Table 2/2


Catalog Number	Article Number	Thickness (T)	Screw Diameter (Sc)	Screw Length (L)	Static Load
SXE019	400056	1.2 mm	5	25mm	1000N
SXE023	400057	1.2 mm	5	25mm	1000N
SXE028	400058	1.2 mm	5	25mm	1000N
SXE035	400059	1.2 mm	5	30mm	1000N
SXE043	400060	1.2 mm	5	30mm	1000N
SXE052	400062	1.2 mm	5	30mm	1300N
SXE058	589310	1.2 mm	5	30mm	1300N
SXE061	589320	1.2 mm	5	30mm	1300N

Catalog Number	Article Number	Thickness (T)	Screw Diameter (Sc)	Screw Length (L)	Static Load
SXE014	400055	1.2 mm	5	25mm	1000N

ADDITIONAL PRODUCT DETAILS

Lining is EPDM rubber.

DIAGRAMS

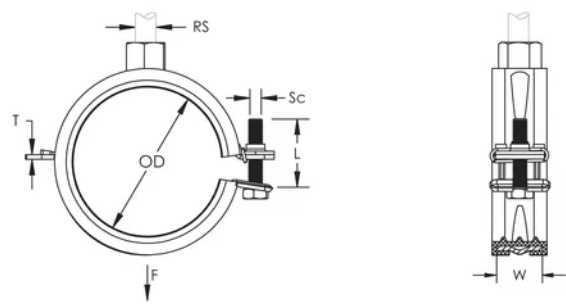

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

