

PBF Two Hole Base Plate for Threaded Pipe



FEATURES

Medium duty with two holes and one nut/adaptor

SPECIFICATIONS

Finish: Electrogalvanized

Material: Сталь


Table 1/2

Catalog Number	Article Number	Gewinde (G)	Длина мм (L)	Width (W)	Thickness (T)	A
PBT050L80	587125	1/2"	80mm	30 mm	3 mm	50 mm
PBT050L120	587120	1/2"	120mm	40 mm	4 mm	81 mm

Table 2/2

Catalog Number	Article Number	B	C
PBT050L80	587125	18 mm	9 mm
PBT050L120	587120	18 mm	11 mm

DIAGRAMS

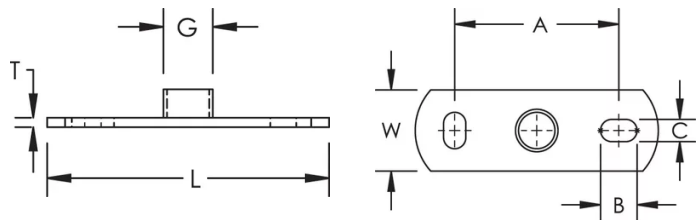

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

