

PEMSA Wire Basket Tray Center Support



CERTIFICATIONS



FEATURES

Ideal for tray widths up to 200mm

Side load access for cable installation

IEC 61537 load rating and earthing compliant

SPECIFICATIONS

Finish: Electrogalvanized

Material: Сталь

Table 1/2


Catalog Number	Article Number	Color	Длина мм (L)	Width (W)	Height (H)	Hole Size (HS)
WBTCTRSPT M10	820420		59mm	35 mm	5 mm	8 - 10 mm
WBTCTRSPT M10BG	820421	Черный	59mm	35 mm	5 mm	8 - 10 mm

CatalogNumber	Article Number	Color	Длина мм (L)	Width (W)	Height (H)	Hole Size (HS)
WBTCTRSPRT M6	820400		59mm	35 mm	5 mm	6 mm

Table 2/2

Catalog Number	Article Number	Certifications
WBTCTRSPRTM10	820420	ANOR EU WTB EG S4 BG, CE, CADDY EU WBT QC
WBTCTRSPRTM10BG	820421	CE, CADDY EU WBT QC, ANOR EU WTB EG S4 BG
WBTCTRSPRTM6	820400	CE, CADDY EU WBT QC

DIAGRAMS

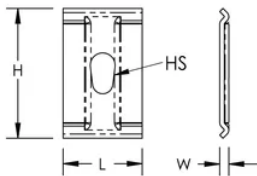

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

