


PEMSA Wire Basket Tray Quick Center Support

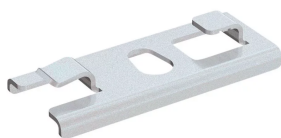

CERTIFICATIONS



FEATURES

Ideal for tray widths up to 200mm

Side load access for cable installation

IEC 61537 load rating and earthing compliant

SPECIFICATIONS

Finish: Electrogalvanized

Material: Сталь

Table 1/2


Catalog Number	Article Number	Color	Длина мм (L)	Width (W)	Height (H)	Hole Size (HS)
WBTQCTRSPT M6	820405		59mm	35 mm	5 mm	6 mm
WBTQCTRSPT M10	820425		59mm	35 mm	5 mm	8 - 10 mm

CatalogNumber	Article Number	Color	Длина мм (L)	Width (W)	Height (H)	Hole Size (HS)
WBTQCTRSPRT M6BG	820406	Черный	59mm	35 mm	5 mm	6 mm

Table 2/2

Catalog Number	Article Number	Static Load	Certifications
WBTQCTRSPRTM6	820405	833N	CE, CADDY EU WBT QC
WBTQCTRSPRTM10	820425	833N	CE, CADDY EU WBT QC, ANOR EU WTB Q
WBTQCTRSPRTM6BG	820406	833N	CE, CADDY EU WBT QC, ANOR EU WTB Q

DIAGRAMS

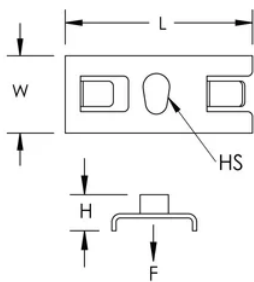

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

