

U-Bolt



FEATURES

Complete with 4 nuts

SPECIFICATIONS

Table 1/2

Catalog Number	Article Number	Material	Finish	Outer Diameter (OD)	NB/DN	Rod Size (RS)
UB4N23M6S6	599485	Stainless Steel 316 (EN 1.4401)		23 mm	10	M6
UB4N027M8S6	597615	Stainless Steel 316 (EN 1.4401)		27 mm	20	M8
UB4N30M6EG	599405	Сталь	Electrogalvanized	30 mm	20	M6
UB4N30M6S6	599490	Stainless Steel 316 (EN 1.4401)		30 mm	20	M6
UB4N36M8EG	599410	Сталь	Electrogalvanized	36 mm	25	M8
UB4N36M8S6	599495	Stainless Steel 316 (EN 1.4401)		36 mm	25	M8
UB4N042M8	599150	Сталь	Electrogalvanized	42 mm	32	M8

CatalogNumber	Article Number	Material	Finish	Outer Diameter (OD)	NB/DN	Rod Size (RS)
UB4N46M6S6	599510	Stainless Steel 316 (EN 1.4401)		46 mm	32	M6
UB4N46M6EG	599415	Сталь	Electrogalvanized	42 mm	32	M8
UB4N049M8	599160	Сталь	Electrogalvanized	49 mm	40	M8
UB4N049M8S6	597645	Stainless Steel 316 (EN 1.4401)		49 mm	40	M8
UB4N52M8S6	599515	Stainless Steel 316 (EN 1.4401)		52 mm	40	M8
UB4N52M8EG	599420	Сталь	Electrogalvanized	49 mm	40	M8
UB4N042M8S6	597635	Stainless Steel 316 (EN 1.4401)		42 mm	32	M8
UB4N64M8S6	599520	Stainless Steel 316 (EN 1.4401)		65 mm	50	M8
UB4N64M8EG	599425	Сталь	Electrogalvanized	60 mm	50	M8
UB4N076M8S6	597665	Stainless Steel 316 (EN 1.4401)		76 mm	65	M8
UB4N74M8EG	599430	Сталь	Electrogalvanized	74 mm	65	M8
UB4N74M8S6	599525	Stainless Steel 316 (EN 1.4401)		74 mm	65	M8
UB4N090M10	599190	Сталь	Electrogalvanized	90 mm	80	M10
UB4N090M8S6	599357	Stainless Steel 316 (EN 1.4401)		90 mm	80	M8
UB4N94M10EG	599440	Сталь	Electrogalvanized	94 mm	80	M10
UB4N94M10S6	599530	Stainless Steel 316 (EN 1.4401)		94 mm	80	M10

CatalogNumber	Article Number	Material	Finish	Outer Diameter (OD)	NB/DN	Rod Size (RS)
UB4N114M10	599200	Сталь	Electrogalvanized	114 mm	100	M10
UB4N114M8S6	599348	Stainless Steel 316 (EN 1.4401)		114 mm	100	M8
UB4N118M10EG	599445	Сталь	Electrogalvanized	118 mm	100	M10
UB4N118M10S6	599535	Stainless Steel 316 (EN 1.4401)		118 mm	100	M10
UB4N140M8	599337	Сталь	Electrogalvanized	140 mm	125	M8
UB4N140M8S6	599350	Stainless Steel 316 (EN 1.4401)		140 mm	125	M8
UB4N146M12EG	599450	Сталь	Electrogalvanized	146 mm	125	M12
UB4N146M12S6	599540	Stainless Steel 316 (EN 1.4401)		146 mm	125	M12
UB4N160M8	599338	Сталь	Electrogalvanized	160 mm		M8
UB4N160M8S6	599351	Stainless Steel 316 (EN 1.4401)		160 mm		M8
UB4N168M12EG	599455	Сталь	Electrogalvanized	168 mm		M12
UB4N168M12S6	599545	Stainless Steel 316 (EN 1.4401)		168 mm		M12
UB4N168M14	599240	Сталь	Electrogalvanized	168 mm	150	M14
UB4N168M8S6	599352	Stainless Steel 316 (EN 1.4401)		168 mm	150	M8

CatalogNumber	Article Number	Material	Finish	Outer Diameter (OD)	NB/DN	Rod Size (RS)
UB4N172M16EG	599460	Сталь	Electrogalvanized	172 mm	150	M16
UB4N172M16S6	599550	Stainless Steel 316 (EN 1.4401)		172 mm	150	M16
UB4N219M10	599341	Сталь	Electrogalvanized	219 mm	200	M10
UB4N219M10S6	599354	Stainless Steel 316 (EN 1.4401)		219 mm	200	M10
UB4N219M16	599250	Сталь	Electrogalvanized	219 mm	200	M16
UB4N224M12S6	599555	Stainless Steel 316 (EN 1.4401)		224 mm	200	M12
UB4N224M16EG	599470	Сталь	Electrogalvanized	224 mm	200	M16
UB4N273M16	599260	Сталь	Electrogalvanized	273 mm	250	M16
UB4N278M16EG	599475	Сталь	Electrogalvanized	278 mm	250	M16
UB4N278M16S6	599560	Stainless Steel 316 (EN 1.4401)		278 mm	250	M16
UB4N323M10	599343	Сталь	Electrogalvanized	323 mm	300	M10
UB4N323M10S6	599356	Stainless Steel 316 (EN 1.4401)		323 mm	300	M10
UB4N329M16EG	599480	Сталь	Electrogalvanized	345 mm	300	M16
UB4N329M16S6	599565	Stainless Steel 316 (EN 1.4401)		345 mm	300	M16


Table 2/2

Catalog Number	Article Number	Height (H)
UB4N23M6S6	599485	50 mm
UB4N027M8S6	597615	58 mm
UB4N30M6EG	599405	60 mm
UB4N30M6S6	599490	60 mm
UB4N36M8EG	599410	70 mm
UB4N36M8S6	599495	70 mm
UB4N042M8	599150	76 mm
UB4N46M6S6	599510	80 mm
UB4N46M6EG	599415	80 mm
UB4N049M8	599160	78 mm
UB4N049M8S6	597645	78 mm
UB4N52M8S6	599515	90 mm
UB4N52M8EG	599420	90 mm
UB4N042M8S6	597635	76 mm
UB4N64M8S6	599520	100 mm
UB4N64M8EG	599425	100 mm
UB4N076M8S6	597665	118 mm
UB4N74M8EG	599430	120 mm

Catalog Number	Article Number	Height (H)
UB4N74M8S6	599525	120 mm
UB4N090M10	599190	125 mm
UB4N090M8S6	599357	125 mm
UB4N94M10EG	599440	140 mm
UB4N94M10S6	599530	140 mm
UB4N114M10	599200	166 mm
UB4N114M8S6	599348	166 mm
UB4N118M10EG	599445	140 mm
UB4N118M10S6	599535	165 mm
UB4N140M8	599337	197 mm
UB4N140M8S6	599350	197 mm
UB4N146M12EG	599450	200 mm
UB4N146M12S6	599540	200 mm
UB4N160M8	599338	214 mm
UB4N160M8S6	599351	214 mm
UB4N168M12EG	599455	220 mm
UB4N168M12S6	599545	220 mm
UB4N168M14	599240	224 mm

Catalog Number	Article Number	Height (H)
UB4N168M8S6	599352	224 mm
UB4N172M16EG	599460	240 mm
UB4N172M16S6	599550	240 mm
UB4N219M10	599341	286 mm
UB4N219M10S6	599354	286 mm
UB4N219M16	599250	286 mm
UB4N224M12S6	599555	295 mm
UB4N224M16EG	599470	295 mm
UB4N273M16	599260	331 mm
UB4N278M16EG	599475	350 mm
UB4N278M16S6	599560	350 mm
UB4N323M10	599343	389 mm
UB4N323M10S6	599356	389 mm
UB4N329M16EG	599480	400 mm
UB4N329M16S6	599565	400 mm

DIAGRAMS

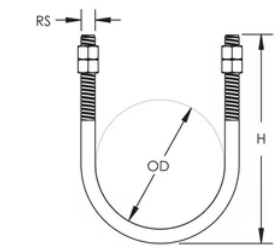

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

