


Стальная двойная дверь Varistar CP, Перфорированная, 3-точечное запирание

Data Solutions

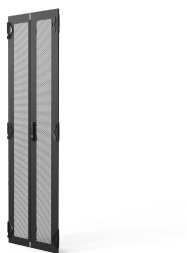

Перфорированная двойная стальная дверь Varistar CP с 3-точечным запиранием и 2 дверными петлями для областей применения с классом защиты IP 20.

FEATURES

Двустворчатая перфорированная стальная дверь с 3-точечным запиранием для обеспечения класса защиты IP

Поворотная ручка с кнопкой, ключ

Угол открытия 180°

Стандартный монтаж, замок на правой двери

Возможность дооснащения профильным DIN-полуцилиндром

SPECIFICATIONS

Locking Type: 3-Point Locking

Product Type: Cabinet Door

Protection Rating: IP20

Material: Сталь

Table 1/2

Catalog Number	Rack Height	Высота мм	Ширина мм	Package Quantity	Color	Color Code
21630-020	42U	2000mm	600mm	1	Black Grey	RAL 7021
21630-021	47U	2200mm	600mm	1	Black Grey	RAL 7021

CatalogNumber	Rack Height	Высота мм	Ширина мм	Package Quantity	Color	Color Code
21630-022	52U	2450mm	600mm	1	Black Grey	RAL 7021
21630-027	42U	2000mm	800mm	1	Black Grey	RAL 7021
21630-028	47U	2200mm	800mm	1	Black Grey	RAL 7021
21630-029	52U	2450mm	800mm	1	Black Grey	RAL 7021
21630-448	24U	1200mm	600mm	1	Black Grey	RAL 7021
21630-449	24U	1200mm	800mm	1	Black Grey	RAL 7021
21630-450	29U	1400mm	600mm	1	Black Grey	RAL 7021
21630-451	29U	1400mm	800mm	1	Black Grey	RAL 7021
21630-452	33U	1600mm	600mm	1	Black Grey	RAL 7021
21630-453	33U	1600mm	800mm	1	Black Grey	RAL 7021
21630-454	38U	1800mm	600mm	1	Black Grey	RAL 7021
21630-455	38U	1800mm	800mm	1	Black Grey	RAL 7021

Table 2/2				
Catalog Number	Complies With	Finish	Type	Works With
21630-020	IEC 61587-1, IEC 61587-3	Powder Coated	Steel Double Door, Perforated	Varistar CP
21630-021	IEC 61587-1, IEC 61587-3	Powder Coated	Steel Double Door, Perforated	Varistar CP
21630-022	IEC 61587-1, IEC 61587-3	Powder Coated	Steel Double Door, Perforated	Varistar CP
21630-027	IEC 61587-1, IEC 61587-3	Powder Coated	Steel Double Door, Perforated	Varistar CP
21630-028	IEC 61587-1, IEC 61587-3	Powder Coated	Steel Double Door, Perforated	Varistar CP

Catalog Number	Complies With	Finish	Type	Works With
21630-029	IEC 61587-1, IEC 61587-3	Powder Coated	Steel Double Door, Perforated	Varistar CP
21630-448	IEC 61587-1, IEC 61587-3	Powder Coated	Steel Double Door, Perforated	Varistar CP
21630-449	IEC 61587-1, IEC 61587-3	Powder Coated	Steel Double Door, Perforated	Varistar CP
21630-450	IEC 61587-1, IEC 61587-3	Powder Coated	Steel Double Door, Perforated	Varistar CP
21630-451	IEC 61587-1, IEC 61587-3	Powder Coated	Steel Double Door, Perforated	Varistar CP
21630-452	IEC 61587-1, IEC 61587-3	Powder Coated	Steel Double Door, Perforated	Varistar CP
21630-453	IEC 61587-1, IEC 61587-3	Powder Coated	Steel Double Door, Perforated	Varistar CP
21630-454	IEC 61587-1, IEC 61587-3	Powder Coated	Steel Double Door, Perforated	Varistar CP
21630-455	IEC 61587-1, IEC 61587-3	Powder Coated	Steel Double Door, Perforated	Varistar CP

ADDITIONAL PRODUCT DETAILS

Профильный DIN-полуцилиндр для поворотной ручки заказывается отдельно

Комплект заземления можно приобрести отдельно.

Please purchase the grounding kit separately.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE