


Cable to Web of Rail Replacement Mold Pair, Signal

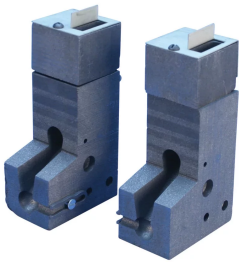

FEATURES

Replacement mold pair designed for the installation of track circuits and jumper bonds to the neutral axis

Sold in pairs

SPECIFICATIONS

Material: Graphite

Table 1/1

Catalog Number	Rail Type	Bond Terminal Style	Conductor Size	Conductor Outer Diameter, Nominal	Welder Style	Bond Clips Included
SBB200R	85 lb to 141 lb T-Rail Sections	1" Tab	10 mm ² Stranded	4.12mm	TB5, T21	Нет
SBB200A	85 lb to 141 lb T-Rail Sections	3/4" XS	3/16" Bondstrand	4.76mm	TB5, T21	Да
SBB200B	85 lb to 141 lb T-Rail Sections	3/4" Tab	3/16" Bondstrand	4.76mm	TB5, T21	Да
SBB200C	85 lb to 141 lb T-Rail Sections	1" Tab	3/16" Bondstrand	4.76mm	TB5, T21	Да
SBB200C12AS	12 lb ASCE	1" Tab	3/16" Bondstrand	4.76mm	T21, TB5	Нет

CatalogNumber	Rail Type	Bond Terminal Style	Conductor Size	Conductor OuterDiameter, Nominal	Welder Style	Bond Clips Included
SBB200D	85 lb to 141 lb T-Rail Sections	1 1/2" Tab	3/16" Bondstrand	4.76mm	T21, TB5	Нет
SBB200G	85 lb to 141 lb T-Rail Sections	1" Tab	3/16" Bondstrand	4.76mm	T21, TB5	Нет
SBB200U	RI60	1" Tab	3/16" Bondstrand	4.76mm	TB5, T21	Нет
SBB200Y	85 lb to 141 lb T-Rail Sections	1" Tab	16 mm ² Concentric	5.18mm	T21, TB5	Нет
SBB200L	85 lb to 141 lb T-Rail Sections	1" Tab	22 mm ² Ropelay	6.1mm	T21, TB5	Нет
SBB200X	85 lb to 141 lb T-Rail Sections	1" Tab	25 mm ² Stranded	6.6mm	TB5, T21	Нет
SBB200P	85 lb to 141 lb T-Rail Sections	1" Tab	35 mm ² Concentric	7.75mm	T21, TB5	Not Required
SBB200E	85 lb to 141 lb T-Rail Sections	1" Tab	5/16" Bondstrand	7.94mm	TB5, T21	Да

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE