


Joint Bond T6 Complete Welder Pair, Signal, 1" Tab Bond Terminal Style, 3/16" Bondstrand

CATALOG NUMBER

SBTBT6D

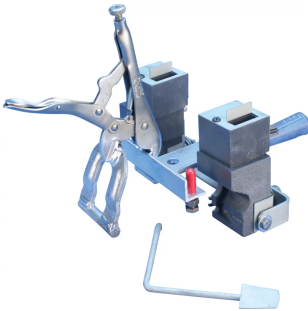

FEATURES

Complete welder assembly provides a convenient means of attaching jumper bonds to the head of the rail, across the joint

Connection is made within the confines of the splice bar

Includes mold cleaner

PRODUCT ATTRIBUTES

Article Number: 715408

Material: Сталь;Graphite;Thermoplastic

Rail Type: 85 lb to 141 lb T-Rail Sections

Bond Terminal Style: 1" Tab

Conductor Size: 3/16" Bondstrand

Conductor Outer Diameter, Nominal: 4.76mm

Bond Length: 247.7mm

Welder Style: T6

Mold Only: HeT

Replacement Mold: SBS5838

Welding Material: SB25 x 2, Sold Separately

Frame: SBS5838F, Sold Separately

Bond Clip: SBS2659 x 2, Sold Separately

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

⚠ WARNING: This product can expose you to chemicals including diisononyl phthalate, which is known to the State of California to cause cancer. For more information go to www.P65Warnings.ca.gov.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE